


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0982680157](#)
Status: **Active**
Overview: [FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers](#)
Description: 1.25mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 178.00mm Cable Length, Tin (Sn) Plating, 10 Circuits

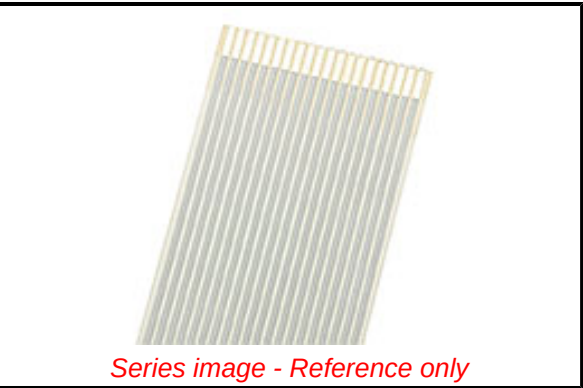

Documents:
[Drawing \(PDF\)](#) [Datasheet \(PDF\)](#)
[Product Specification PS-98268-001-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Cable
Series	98268
Comments	Contacts on the same side, Type A
Crimp Quality Equipment	Yes
Overview	FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers
Product Name	Premo-Flex FFC Jumper
UPC	756054775479
Physical	
Cable Length	178.00mm
Circuits (Loaded)	10
Contact Layout Type	A (same side)
Material - Plating Mating	Tin
Net Weight	1.545/g
Packaging Type	Bag
Pitch - Mating Interface	1.25mm
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	N/A
Wire/Cable Type	Flat Flex Cable
Electrical	
Current - Maximum per Contact	1.4A
Voltage - Maximum	60V AC
Material Info	
Reference - Drawing Numbers	
Product Specification	PS-98268-001-001
Sales Drawing	SD-98268-001-001

EU ELV Not Reviewed	
EU RoHS Not Reviewed REACH SVHC Not Reviewed Halogen-Free Status Not Reviewed	China RoHS
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series
[98268 Series](#)

Mates With
Molex FFC – FPC connector. Be sure to match like plating.

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[98268-0157](#)