

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0982761006
Status: Active
Overview: NSCC - New Standard Casing Contact
Description: 3.33mm / 6.00mm Pitch Hybrid Male Inline Housing, Dual Row, 16 Circuits, Gray

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[Application Specification AS-98276-001-001 \(PDF\)](#)
[Packaging Specification PK-98276-001-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)


General
Product Family Crimp Housings
Series 98276
Application Power, Wire-to-Wire
Comments For current designation please refer to FCI Sicma terminal specification for 1.50 and 2.80mm terminals.
Overview NSCC - New Standard Casing Contact
Product Name NSCC
UPC 822348213221

Physical
Circuits (maximum) 16
Circuits Detail 4x2.8mm 12x1.5mm male terminals
Color - Resin Natural, Natural (White)
Gender Plug
Glow-Wire Capable No
Lock to Mating Part Yes
Material - Resin Polyester, Polyester Alloy
Net Weight 12.361/g
Number of Rows 2
Packaging Type Bag
Panel Mount No
Pitch - Mating Interface 3.33mm, 6.00mm
Polarized to Mating Part Yes
Ports 1
Stackable No
Temperature Range - Operating -40° to +85°C

Solder Process Data
Lead-freeProcess Capability N/A

Material Info

Reference - Drawing Numbers
Application Specification AS-98276-001-001
Packaging Specification PK-98276-001-001
Sales Drawing SD-98276-001-001

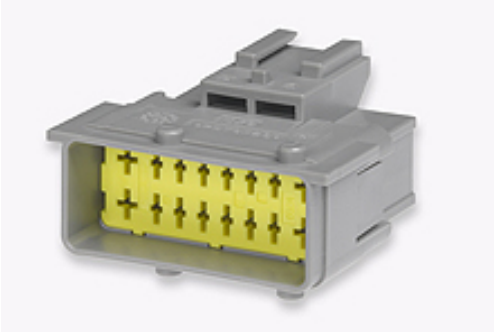

Series image - Reference only

EU ELV
Compliant

EU RoHS
Compliant
REACH SVHC
Not Contained Per -
D(2021)4569-DC (8
July 2021)
Halogen-Free
Status
Not Relevant
For more information, please visit [Contact US](#)

China ROHS	Not Relevant
ELV	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series
98276 Series

Mates With
982731006

Use With
1.5 and 2.8mm FCI Sicma Male Terminals

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[98276-1006](#)