

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0982980002

Status:


Active

Overview:

MOX Products

Description:

2.54mm Pitch MOX Receptacle Housing, 6 Circuits, Breakable, Dual Row, White

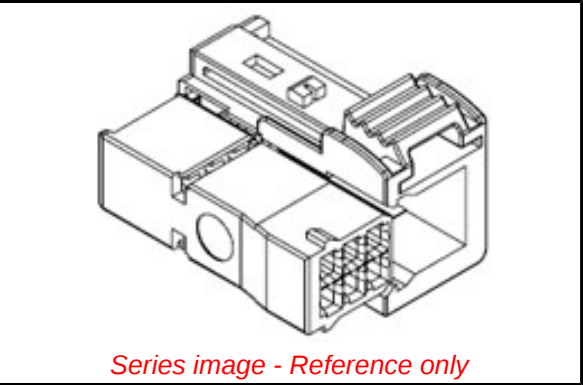

Documents:

[Drawing \(PDF\)](#)

[Product Specification PS-98298-001-001 \(PDF\)](#)

[Application Specification 982980001-AS-CH-000 \(PDF\)](#)

[Application Specification AS-98298-001-001 \(PDF\)](#)

[Packaging Specification PK-98298-001-001 \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Crimp Housings
Series	98298
Application	Power, Wire-to-Board
Comments	2x3 Circuits
Overview	MOX Products
Product Name	MOX
UPC	756054595350
Physical	
Circuits (maximum)	6
Color - Resin	White
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Polyester
Net Weight	2.530/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.54mm
Pitch - Termination Interface	2.54mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C
Electrical	
Current - Maximum per Contact	6.0A
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Reference - Drawing Numbers	
Application Specification	982980001-AS-CH-000, AS-98298-001-001
Packaging Specification	PK-98298-001-001
Product Specification	PS-98298-001-001
Sales Drawing	SD-98298-002-001, SD-98298-003-001

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - D(2021)4569-DC (8 July 2021)

Halogen-Free

Status

Not Relevant

For more information, please visit

Contact US

China ROHS

ELV

RoHS Phthalates

Not Relevant

Compliant

Not Contained

Search Parts in this Series

98298 Series

Mates With

Please Contact Molex for Details

Use With

98658 MOX Crimp Terminal

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[98298-0002](#)