

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0984381002

Status:

Active

Description:

5.00mm Pitch NSCC/SICMA Female Wire-to-Board Housing, for 2.80mm Tab, with Bridges, Dual Row, 6 Circuits, Black


Documents:

Drawing (PDF)

Application Specification AS-98438-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Crimp Housings
Series	98438
Application	Power, Wire-to-Board
Comments	For current designation please refer to FCI Sicma terminal specification for 2.80mm terminals.
Product Name	NSCC
UPC	822348873197
Physical	
Circuits (maximum)	6
Color - Resin	Black
Gender	Receptacle
Glow-Wire Capable	No
Lock to Mating Part	Yes
Material - Resin	Polyester
Net Weight	5.162/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	5.00mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Reference - Drawing Numbers	
Application Specification	AS-98438-001-001
Sales Drawing	SD-98438-001

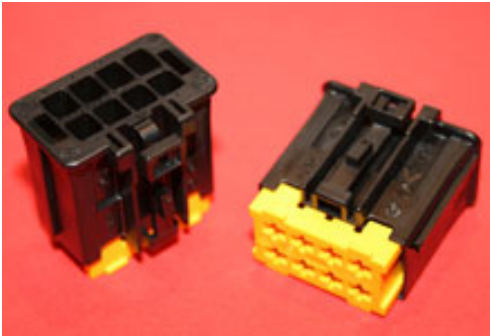

Series image - Reference only

EU ELV	
Compliant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - ED/71/2019 (16 July 2019)	
Halogen-Free	
Status	
Not Relevant	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series

98438 Series

Mates With

98898 UCC2 Terminals

Use With

98898

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

98438-1002