


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

**Part Number:** [0987841003](#)  
**Status:** **Active**  
**Overview:** NSCC - New Standard Casing Contact  
**Description:** NSCC Receptacle Connector 3.33mm Pitch, 1.50mm, Shorting Bar, Long, 5 Circuit, Green

**Documents:**  
[3D Model](#) [Application Specification AS-98784-005-CH-001 \(PDF\)](#)  
[Drawing \(PDF\)](#) [Packaging Specification PK-98784-001-001 \(PDF\)](#)  
[Application Specification AS-98784-005-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

|                                    |                                       |
|------------------------------------|---------------------------------------|
| <b>General</b>                     |                                       |
| Product Family                     | Crimp Housings                        |
| Series                             | 98784                                 |
| Application                        | Wire-to-Wire                          |
| Overview                           | NSCC - New Standard Casing Contact    |
| Product Name                       | NSCC                                  |
| UPC                                | 822350978941                          |
| <b>Physical</b>                    |                                       |
| Circuits (maximum)                 | 5                                     |
| Circuits Detail                    | 5                                     |
| Color - Resin                      | Green                                 |
| Gender                             | Receptacle                            |
| Glow-Wire Capable                  | No                                    |
| Lock to Mating Part                | Yes                                   |
| Material - Resin                   | PBT                                   |
| Net Weight                         | 4.920/g                               |
| Number of Rows                     | 1                                     |
| Packaging Type                     | Carton                                |
| Panel Mount                        | No                                    |
| Pitch - Mating Interface           | 3.33mm                                |
| Polarized to Mating Part           | Yes                                   |
| Stackable                          | No                                    |
| Temperature Range - Operating      | -40° to +85°C                         |
| <b>Solder Process Data</b>         |                                       |
| Lead-freeProcess Capability        | N/A                                   |
| <b>Material Info</b>               |                                       |
| <b>Reference - Drawing Numbers</b> |                                       |
| Application Specification          | AS-98784-005-001, AS-98784-005-CH-001 |
| Packaging Specification            | PK-98784-001-001                      |
| Sales Drawing                      | SD-98784-001                          |

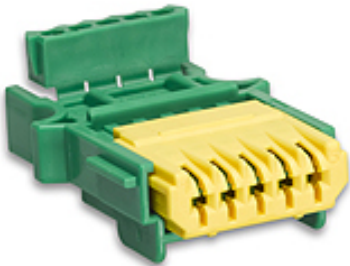

Series image - Reference only

|                                                               |                   |
|---------------------------------------------------------------|-------------------|
| <b>EU ELV</b>                                                 |                   |
| <b>Compliant</b>                                              |                   |
| <b>EU RoHS</b>                                                | <b>China RoHS</b> |
| <b>Compliant</b>                                              |                   |
| <b>REACH SVHC</b>                                             |                   |
| Not Contained Per - D(2020)4578-DC (25 June 2020)             |                   |
| <b>Halogen-Free</b>                                           |                   |
| <b>Status</b>                                                 |                   |
| <b>Not Relevant</b>                                           |                   |
| For more information, please visit <a href="#">Contact US</a> |                   |
| China ROHS                                                    | Not Relevant      |
| ELV                                                           | Compliant         |
| RoHS Phthalates                                               | Not Contained     |

**Search Parts in this Series**  
[98784](#) Series

**Mates With**  
[987811003](#) NSCC 3.33mm Pitch Long Version Male Housing

**Use With**  
[98897](#) NSCC Receptacle Terminal

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[98784-1003](#)