

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0987841004](#)
Status: **Active**
Overview: NSCC - New Standard Casing Contact
Description: NSCC Receptacle Connector 3.33mm Pitch, 1.50mm, Shorting Bar, Long, 5 Circuit, Blue

Documents:	
3D Model	Application Specification AS-98784-005-CH-001 (PDF)
Drawing (PDF)	Packaging Specification PK-98784-001-001 (PDF)
Application Specification AS-98784-005-001 (PDF)	RoHS Certificate of Compliance (PDF)


General	
Product Family	Crimp Housings
Series	98784
Application	Wire-to-Wire
Overview	NSCC - New Standard Casing Contact
Product Name	NSCC
UPC	800756645377

Physical	
Circuits (maximum)	5
Circuits Detail	5
Color - Resin	Blue
Gender	Receptacle
Glow-Wire Capable	No
Lock to Mating Part	Yes
Material - Resin	PBT
Net Weight	4.920/g
Number of Rows	1
Packaging Type	Carton
Panel Mount	No
Pitch - Mating Interface	3.33mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +85°C

Solder Process Data	
Lead-freeProcess Capability	N/A

Material Info

Reference - Drawing Numbers	
Application Specification	AS-98784-005-001, AS-98784-005-CH-001
Packaging Specification	PK-98784-001-001
Sales Drawing	SD-98784-001

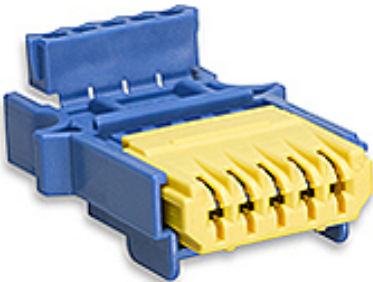

Series image - Reference only

EU ELV	
Compliant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2020)4578-DC (25 June 2020)	
Halogen-Free	
Status	
Not Relevant	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series
[98784](#) Series

Mates With
[987811004](#) NSCC 3.33mm Pitch Long Version Male Housing

Use With
[98897](#) NSCC Receptacle Terminal

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[98784-1004](#)