

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0987841013

Status:


Active

Overview:

NSCC - New Standard Casing Contact

Description:

NSCC Receptacle Connector 3.33mm Pitch, 1.50mm, Shorting Bar, Short, 5 Circuit, Green

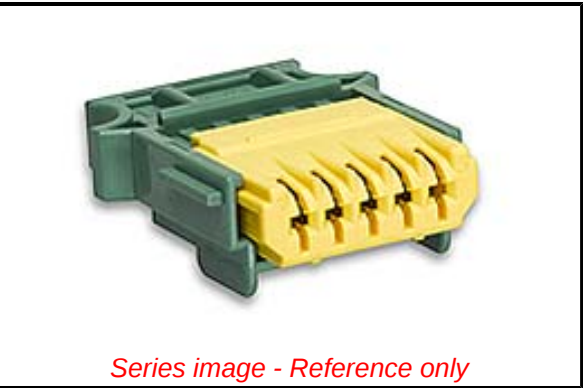

Series image - Reference only

Documents:	
3D Model	Application Specification AS-98784-005-CH-001 (PDF)
Drawing (PDF)	Packaging Specification PK-98784-001-001 (PDF)
Application Specification AS-98784-005-001 (PDF)	RoHS Certificate of Compliance (PDF)

General		EU ELV	
Product Family	Crimp Housings	Compliant	
Series	98784		
Application	Wire-to-Wire	EU RoHS	China RoHS
Overview	NSCC - New Standard Casing Contact	Compliant	
Product Name	NSCC	REACH SVHC	
UPC	822350785891	Contained Per -	
Physical		D(2020)4578-DC (25	
Circuits (maximum)	5	June 2020)	
Circuits Detail	5	Methylhexahydrophthalic	
Color - Resin	Green	anhydride	
Gender	Receptacle	Dodecachloropentacyclo[12.2.1.16,9.02,13.05,10]o	
Glow-Wire Capable	No	Pyrene	
Lock to Mating Part	Yes	Nonadecafluorodecanoic	
Material - Resin	PBT	acid (PFDA) and its	
Net Weight	4.200/g	sodiu	
Number of Rows	1	Zirconia	
Packaging Type	Carton	Aluminosilicate	
Panel Mount	No	Refractory Ceramic	
Pitch - Mating Interface	3.33mm	Fibr	
Polarized to Mating Part	Yes	Aluminosilicate	
Stackable	No	Refractory Ceramic	
Temperature Range - Operating	-40° to +85°C	Fibres	
Solder Process Data		Boric acid	
Lead-freeProcess Capability	N/A	n-pentyl-	
Material Info		isopentylphthalate	
Reference - Drawing Numbers		1,2-	
Application Specification	AS-98784-005-001, AS-98784-005-CH-001	Benzenedicarboxylic	
Packaging Specification	PK-98784-001-001	acid, dipentyl ester, br	
Sales Drawing	SD-98784-001	diisohexyl phthalate	
		1,2-	
		Benzenedicarboxylic	
		acid, dihexyl ester,	
		bra	
		2-(2H-benzotriazol-2-	
		yl)-4-(tert-butyl)-6-	
		(sec-b	
		Ammonium-	
		pentadecafluorooctanoate	
		disodium 4-	
		amino-3-[[4'-[(2,4-	
		diaminophenyl)azo]	
		1,3-propanesultone	
		dibutyltin dichloride	

1,2-Benzenedicarboxylic acid, bis(3-methylbutyl) disodium 3,3'-[[1,1'-biphenyl]-4,4'-diylbis(azo) dihexyl phthalate (DnHP)
Fatty acids, C16-18, lead salts
Silicic acid (H2Si2O5), barium salt (1:1), lead-cadmium hydroxide
Lead-titanium-trioxide lead dinitrate
pyrochlore, antimony lead yellow
cadmium orange lead
cadmium oxide (non-pyrophoric)
Diboron-trioxide bis(pentabromophenyl) ether
1,2-bis(2-methoxyethoxy)ethane
1,2-Benzenedicarboxylic acid, di-C6-8-branched a
1,2-Benzenedicarboxylic acid, di-C7-11-branched
Strontium-chromate
Boric acid, disodium salt, hydrate
Lead sulfochromate yellow
Lead chromate molybdate sulfate red
lead chromate

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS	Not Relevant
ELV	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series
[98784](#) Series

Mates With
[987811013](#) NSCC 3.33mm Pitch Short Version Male Housing

Use With
[98897](#) NSCC Receptacle Terminal

This document was generated on 01/21/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[98784-1013](#)