

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0987841014

Status:


Active

Overview:

NSCC - New Standard Casing Contact

Description:

NSCC Receptacle Connector 3.33mm Pitch, 1.50mm, Shorting Bar, Short, 5 Circuit, Blue

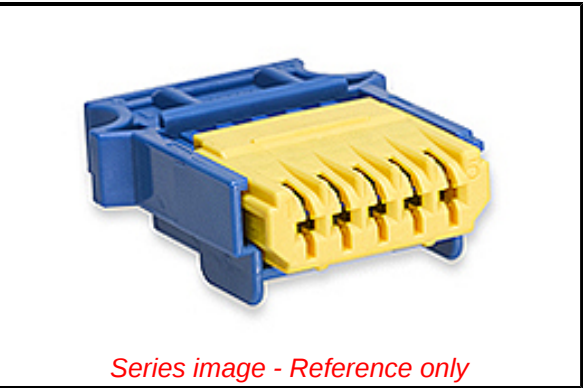

Documents:	
3D Model	Application Specification AS-98784-005-CH-001 (PDF)
Drawing (PDF)	Packaging Specification PK-98784-001-001 (PDF)
Application Specification AS-98784-005-001 (PDF)	RoHS Certificate of Compliance (PDF)

General	
Product Family	Crimp Housings
Series	98784
Application	Wire-to-Wire
Overview	NSCC - New Standard Casing Contact
Product Name	NSCC
UPC	822350787123
Physical	
Circuits (maximum)	5
Circuits Detail	5
Color - Resin	Blue
Gender	Receptacle
Glow-Wire Capable	No
Lock to Mating Part	Yes
Material - Resin	PBT
Net Weight	4.200/g
Number of Rows	1
Packaging Type	Carton
Panel Mount	No
Pitch - Mating Interface	3.33mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +85°C
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Reference - Drawing Numbers	
Application Specification	AS-98784-005-001, AS-98784-005-CH-001
Packaging Specification	PK-98784-001-001
Sales Drawing	SD-98784-001

EU ELV Compliant	
EU RoHS Compliant	China RoHS
REACH SVHC Not Contained Per - D(2020)4578-DC (25 June 2020)	
Halogen-Free Status Not Relevant	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series
98784 Series

Mates With
987811014 NSCC 3.33mm Pitch Short
Version Male Housing

Use With
98897 NSCC Receptacle Terminal

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[98784-1014](#)