

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:


1040921000

Status:

Active

Description:

IllumiMate 1.25mm Pitch Wire-to-Board Crimp Housing, Single Row, 10 Circuits, Natural

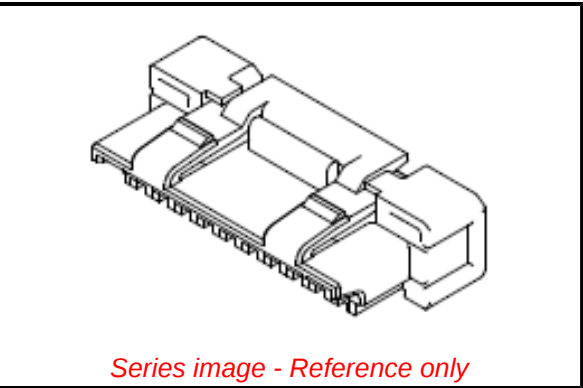

Documents:	
3D Model	Packaging Specification PK-104092-001-001 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-104091-001-001 (PDF)	

General	
Product Family	Crimp Housings
Series	104092
Application	Signal, Wire-to-Board
Product Name	IllumiMate
UPC	884982468672
Physical	
Circuits (maximum)	10
Color - Resin	Natural
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	High Temperature Thermoplastic
Net Weight	0.270/g
Number of Rows	1
Packaging Type	Embossed Tape on Reel
Panel Mount	No
Pitch - Mating Interface	1.25mm
Polarized to Mating Part	Yes
Temperature Range - Operating	-25° to +130°C
Electrical	
Current - Maximum per Contact	1.5A
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Reference - Drawing Numbers	
Packaging Specification	PK-104092-001-001
Product Specification	PS-104091-001-001
Sales Drawing	SD-104092-002

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - ED/71/2019 (16 July 2019)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
104092 Series
Mates With
IllumiMate 1.25mm Pitch Wire-to-Board Header 1040911020
Use With
IllumiMate 1.25mm Wire-to-Board Connector 1045216001

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[104092-1000](#)