

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1040922500](#)
Status: **Active**
Description: IllumiMate 1.25mm Pitch Wire-to-Board Crimp Housing, Single Row, 25 Circuits

Documents:

[3D Model](#) [Packaging Specification PK-104092-001-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-104091-001-001 \(PDF\)](#)

General

Product Family Crimp Housings
Series [104092](#)
Application Signal, Wire-to-Board
Product Name IllumiMate
UPC 887191147550

Physical

Circuits (maximum) 25
Color - Resin Natural
Gender Receptacle
Glow-Wire Compliant No
Keying to Mating Part None
Lock to Mating Part Yes
Material - Resin High Temperature Thermoplastic
Net Weight 0.590/g
Number of Rows 1
Packaging Type Embossed Tape on Reel
Panel Mount No
Pitch - Mating Interface 1.25mm
Polarized to Mating Part Yes
Temperature Range - Operating -25°C to +130°C

Electrical

Current - Maximum per Contact 1.5A


Solder Process Data

Lead-freeProcess Capability N/A

Material Info

Reference - Drawing Numbers

Packaging Specification PK-104092-001-001
Product Specification PS-104091-001-001
Sales Drawing SD-104092-007

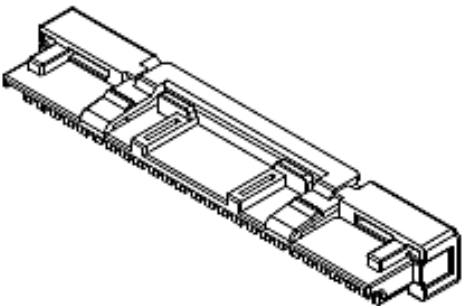

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
ED/30/2017 (7 July
2017)

Halogen-Free

Status

Low-Halogen

**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[104092](#) Series

Mates With

[104091-2520](#)

Use With

[104521-6001](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[104092-2500](#)