

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1054550101

Status:


Active

Overview:

USB Connectors: USB Type-A, USB Type-B, and USB Type-C Plugs and Receptacles

Description:

Universal Serial Bus (USB) Shielded I/O Receptacle, Type C, Right-Angle, Mid-Mount, Surface Mount, Gold (Au) Flash over 0.75µm Palladium Nickel Plating, 0.70mm Solder Tab

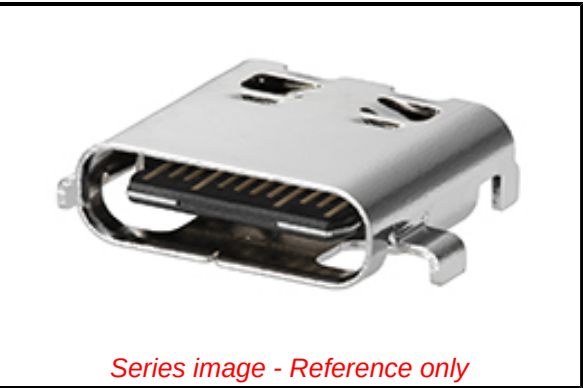

Series image - Reference only

Documents:

- 3D Model

3D Model (PDF)

Drawing (PDF)

Product Specification PS-105448-001-001 (PDF)
- Packaging Specification PK-105455-001-000 (PDF)

Datasheet (PDF)

RoHS Certificate of Compliance (PDF)

General

Product Family	I/O Connectors
Series	105455
Application	Wire-to-Board
Component Type	Receptacle
Overview	USB Connectors: USB Type-A, USB Type-B, and USB Type-C Plugs and Receptacles
Product Name	USB
Standard	USB 3.1
Type	C
UPC	889056733250

Physical

Circuits (Loaded)	24
Circuits (maximum)	24
Color - Resin	Black
Durability (mating cycles max)	10000
Gender	Female
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Metal	Copper Alloy
Material - Plating Mating	Gold over Palladium Nickel
Material - Plating Termination	Gold
Material - Resin	High Temperature Thermoplastic
Mounting Style	Mid-Mount
Net Weight	0.530/g
Number of Rows	2
Orientation	Right Angle
PCB Locator	Yes
PCB Retention	None
PCB Thickness - Recommended	0.60mm, 0.70mm, 0.80mm
Packaging Type	Embossed Tape on Reel
Panel Mount	Yes
Pitch - Mating Interface	0.50mm
Pitch - Termination Interface	0.50mm
Plating min - Mating	0.051µm (Au), 0.750µm (PdNi)
Plating min - Termination	0.051µm
Polarized to Mating Part	No
Polarized to PCB	Yes
Ports	1
Surface Mount Compatible (SMC)	Yes
Temperature Range - Operating	-30° to +85°C
Termination Interface: Style	Surface Mount
Waterproof / Dustproof	No

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China RoHS

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

105455 Series

Mates With

USB Type C Plug/Cable

Electrical

Current - Maximum per Contact	0.25A,1.25A,5.0A, See Product Specification
Grounding to Panel	None
Shield Type	Full Shield
Shielded	Yes
Voltage - Maximum	30V AC/DC

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-105455-001-000
Product Specification	PS-105448-001-001
Sales Drawing	SD-105455-001-001

This document was generated on 10/05/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[105455-0101](#)