

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1061210201

Status:

Active

Overview:

Optical Connectivity Solutions

Description:

LC Adapter, Eight Port, Green Body, Ceramic Alignment Sleeve, Screw Mount Style, LC Footprint, No Shutter

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Datasheet (PDF)

General

Product Family

Fiber Optic Adapters

Series

106121

Component Type

Standard

Mode

Multimode Enhanced

Overview

Optical Connectivity Solutions

Product Name

LC

Type

Adapter

UPC

884982829404

Physical

Alignment Sleeve

Ceramic

Angled Physical Contact (APC)

Yes

Color - Resin

Green

Ferrule Material

Ceramic

Gender

Female-Female

Material - Housing

Polymer

Mounting Style

Screws

Net Weight

20.800/g

Orientation

Straight

Panel Mount

With Flange

Ports

8

Shutter

No

Electrical

Shield Type

N/A

Shielded


No

Material Info

Reference - Drawing Numbers

Sales Drawing

SD-106121-0200-001

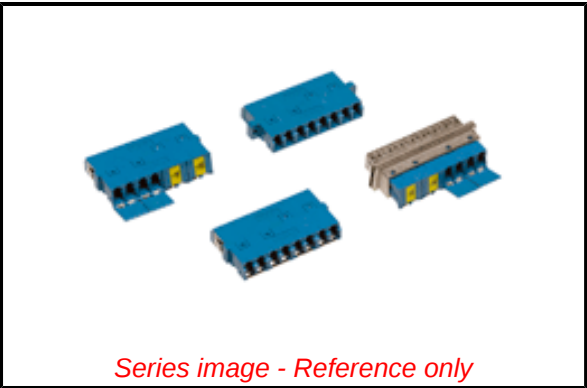

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Contained Per -
D(2021)4569-DC (8
July 2021)
bis(2-(2-
methoxyethoxy)ethyl)
ether
Benzo(ghi)perylene
Octanoic acid,
2,2,3,3,4,4,5,5,6,6,7,7,8,8,8-
pen
Dodecamethylcyclhexasiloxane
Decamethylcyclopentasiloxane
Octamethylcyclotetrasiloxane
Disodium 3,3'-[[1,1'-
Biphenyl]-4,4'-
Diylbis(Azo)
1,2-
Benzenedicarboxylic
acid, bis(3-
methylbutyl)
1,2-diethoxyethane
1,3-Propanesultone
Ammonium-
pentadecafluorooctanoate
Disodium-octaborate
2-ethylhexyl 10-
ethyl-4,4-dioctyl-7-
oxo-8-oxa-3,
Dibutylbis(pentane-2,4-
dionato-O,O')tin
2-(2H-Benzotriazol-2-
yl)-4,6-
ditertpentylphenol
Terphenyl,
hydrogenated
diisohexyl phthalate
1,2-
Benzenedicarboxylic
acid, dipentyl ester, br

n-pentyl-
isopentylphthalate
Zirconia
Aluminosilicate
Refractory Ceramic
Fibr
Nonadecafluorodecanoic
acid (PFDA) and its
sodiu
Tris(4-nonylphenyl,
branched and linear)
phosphi
Fluoranthene
Pyrene
Dodecachloropentacyclo[12.2.1.16,9.02,13.05,10]o
Diocetyl tin dilaurate,
stannane, dioctyl-,
bis(co
Methylhexahydrophthalic
anhydride
Perfluorohexane-1-
sulphonic acid and its
salts
Dipentyl phthalate
Lead chromate
Tris(2-chloroethyl)
phosphate
Boric acid, disodium
salt, hydrate
Strontium-chromate
1,2-
Benzenedicarboxylic
acid, di-C7-11-
branched
bis(2-methoxyethyl)
ether
Pentazinc-chromate-
octahydroxide
1,2-
Benzenedicarboxylic
acid, bis(2-
methoxyethyl
1,2-bis(2-
methoxyethoxy)ethane
Diboron-trioxide
Cadmium-oxide
Cadmium-sulphide
Lead(II,IV)-oxide
Lead
pyrochlore, antimony
lead yellow
Lead-dinitrate
Lead oxide sulfate
(Pb2O(SO4))
Lead-titanium-trioxide
Trilead-dioxide-
phosphonate
Dioxobis(stearato)trilead
Lead titanium
zirconium oxide
Cadmium Hydroxide
Sulfurous Acid, Lead
Salt, Dibasic

Silicic acid (H2Si2O5),
barium salt (1:1),
lead-
Fatty Acids, C16-18,
Lead Salts
Dicyclohexyl-
phthalate
Dihexyl-phthalate
Phenanthrene
Halogen-Free
Status
Not Low-Halogen
For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[106121](#) Series

This document was generated on 09/07/2021
PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[106121-0201](#)