

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1062250035](#)  
**Status:** **Active**  
**Overview:** [Optical Connectivity Solutions](#)  
**Description:** MPO Female-to-MPO Female Trunk Cable Assembly, 9/125µm, 4.80mm, Singlemode, 12 Fiber, Plenum, OS2, 50.0m Length, Yellow

**Documents:**

[Drawing \(PDF\)](#)

[Datasheet \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Fiber Optic Assemblies
Series	<a href="#">106225</a>
Boot Type	Straight
Connector to Connector	MPO-to-MPO
Mode	Singlemode
Overview	<a href="#">Optical Connectivity Solutions</a>
Product Name	MPO
UPC	191128250467


**Physical**

Cable Length	50.0m
Cable Size	4.80mm
Fiber (Core/Cladding)	9/125µm
Net Weight	1094.700/g
Single Ended	No
Wire/Cable Type	12 Fiber OS2 Plenum

**Material Info**

**Reference - Drawing Numbers**

Sales Drawing	1062250025-000
---------------	----------------

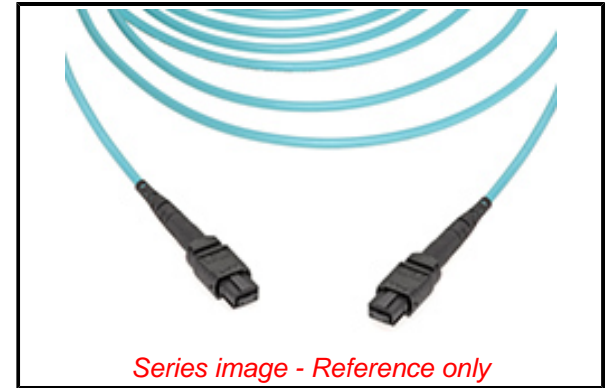

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant with Exemption 6(c)**

**REACH SVHC**

Contained Per -  
D(2021)4569-DC (8  
July 2021)

Lead

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

50 Image

Not Relevant

Not Contained

**Search Parts in this Series**

[106225 Series](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[106225-0035](#)