


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1062841020](#)
Status: **Active**
Overview: [Optical Connectivity Solutions](#)
Description: CXP Optical Cable Assembly (iPass+), MTP-to-MTP, Multimode, 50/125µm, Round Cable Assembly, Straight Boot, High Bandwidth, OFNR, Cable Diameter 4.50mm, Cable Length 20.00m

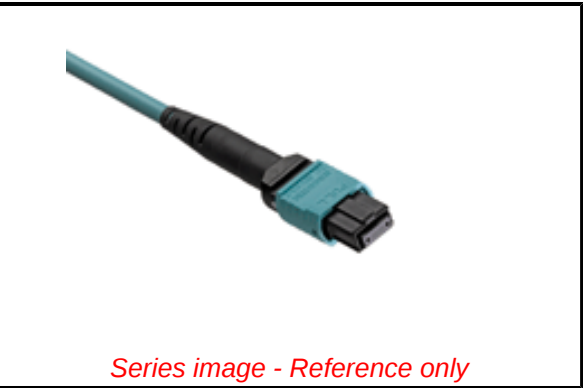

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Fiber Optic Assemblies
Series	106284
Boot Type	Straight
Connector to Connector	MTP-to-MTP
Mode	Multimode
Overview	Optical Connectivity Solutions
Product Name	CXP, iPass+, MTP
UPC	883906550165
Physical	
Cable Length	20.0m
Cable Size	3.80mm
Fiber (Core/Cladding)	50/125µm
Net Weight	332.300/g
Single Ended	No
Wire/Cable Type	Fiber Optic, Round
Material Info	
Reference - Drawing Numbers	
Sales Drawing	SD-106284-0001-001

EU ELV Not Relevant	
EU RoHS Compliant REACH SVHC Not Contained Per - D(2021)4569-DC (8 July 2021) Halogen-Free Status Not Low-Halogen For more information, please visit Contact US	China RoHS
China ROHS ELV RoHS Phthalates	Green Image Not Relevant Not Contained

Search Parts in this Series 106284 Series
Mates With CXP Optical Transceivers

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[106284-1020](#)