


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1120110036](#)
Status: **Active**
Overview: [PC Network Interface Cards](#)
Description: SST PB3 Card, PROFIBUS DP Master/Slave, 2 Channels, PCI 3.3/ 5V -DLL/LIB - Control, Bulk of 25 - Conformal Coated

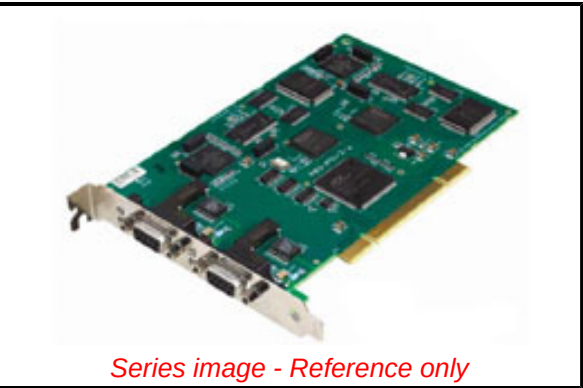

Series image - Reference only

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Network Interface
Series	112011
Application	IO Control
Approvals	CE certified
Comments	2 channels, conformal coated, bulk of 25 units., 2 channels, conformal coated, bulk of 25 units.
Communication Speed	PROFIBUS 9.6 kbps to 12 Mbps
Exclude SD Check	Yes
Mounting Style	PC Slot
Operating System	Windows7, Windows8/8.1, Windows Server 2003, Windows Server 2008, Windows Server 2012, Windows Vista, WindowsXP
Overview	PC Network Interface Cards
Product Name	SST
Protocol	PROFIBUS
Protocol Detail	PROFIBUS DPV0 Master, PROFIBUS DPV0 Slave, PROFIBUS DPV1 Master
Slot	Universal PCI 3.3V/5V
Software Downloads	SST-PB3-PCU-2
Type	PROFIBUS Card
UPC	78172543133
Physical	
Channels	2
Interface	CommDTM, DLL, OPC DA
Net Weight	140.000/g
Network Connection Type	PROFIBUS D-Sub Female (9 pin)
Packaging Type	Carton
Processor	ColdFIRE 5272
Temperature Range - Operating	0°C to +60°C
Electrical	
EMC	EN 61000-3-2, EN 61000-3-3, IEC 61000-6-2
Supply Voltage	3.3/5V
Material Info	
Engineering Number	SST-PB3-PCU-2-B-CC

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China RoHS

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

[112011](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1120110036](#)