

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1120925010

Status:


Active

Overview:

IP67-Rated HarshIO Modules

Description:

Brad HarshIO DeviceNet Module, Compact 30mm, IP67, 8 Ports M8, 8 Outputs, PNP, 3 Pole Power

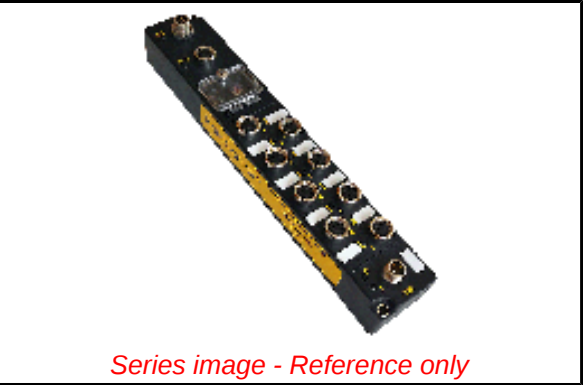

Documents:

[Drawing \(PDF\)](#)

[Product Literature \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Industrial I/O Modules
Series	112092
Application	Filling and Packaging Machines, Machine Tool Industry, Material Handling Systems
Approvals	ODVA, UL, cUL, CE
IP Rating	IP67
Overview	IP67-Rated HarshIO Modules
Product Literature Order No	987651-5351
Product Name	HarshIO DeviceNet
Protocol	DeviceNet
Software Downloads	TBDDN-808P-H44
UPC	887191641966
Physical	
Bus Input	5-pole Nano-Change (M8), B-Coded, Male
Bus Output	5-pole Nano-Change (M8), B-Coded, Female
Format	Compact (30mm)
Housing Width	30.00mm
I/O Connector	3-pole Nano-Change (M8), Male
I/O Ports	8x M8
I/O Signal Mix	8 output
Mechanical Shock	10G, 11ms, 3 AXIS
Power Input	3-pole Nano-Change (M8), Male
Power Output	None
Temperature Range - Operating	0°C to +70°C
Vibration	IEC 60068-2-6
Electrical	
Current - Maximum Output	2.0A per Channel
Input Delay	3 ms
Input Device Supply	140 mA per port at 25°C
Input Type	PNP or Dry Contact
Material Info	
Engineering Number	TBDDN-808P-H44
Reference - Drawing Numbers	
Sales Drawing	1120925010-000

EU ELV	
Not Reviewed	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

112092 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[112092-5010](#)