


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1200060592](#)
Status: **Active**
Overview: [Brad Micro-Change \(M12\) Connectors](#)
Description: Micro-Change (M12) Single-Ended Cordset, 4 Poles, Male (90°) to Pigtail, 0.34mm² PUR/PVC Cable 2.0m (6.56') Length

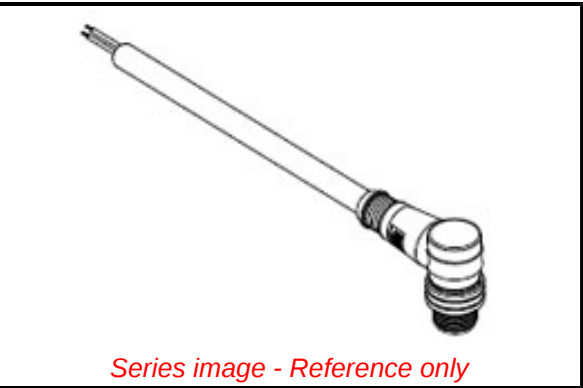

Series image - Reference only

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Industrial Cordsets
Series	120006
Connector End A	Micro-Change (M12)
Connector End B	Pigtail
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	Brad Micro-Change (M12) Connectors
Product Name	Micro-Change (M12)
Protocol	N/A
Region	Europe
Type	Single Ended
UPC	883906068219

Physical	
Cable Diameter	5.30mm (.209")
Cable Length	2.0m (6.56')
Color - Cable Jacket	Black
Coupling Style	Threaded
Gender	Male-Pigtail
Keyway	Single
LED Indicator	No
Material - Cable Jacket	PUR/PVC
Material - Connector Body	PUR
Material - Coupling Nut	Nickel-plated Brass
Material - O-Ring	Fluoro-elastomer
Material - Plating Mating	Gold
Net Weight	83.107/g
Orientation	90° to Pigtail
Poles	4
Temperature Range - Operating	-20° to +80°C
Wire Size AWG	N/A
Wire/Cable Type	EU Cable

Electrical	
Current - Maximum per Contact	4.0A
Voltage - Maximum	250V AC/DC

Material Info	
Engineering Number	804007P03M020

Reference - Drawing Numbers	
Sales Drawing	1200659138-000

EU ELV
Not Reviewed

EU RoHS
Not Reviewed
REACH SVHC
Not Reviewed
Halogen-Free
Status
Not Reviewed

China RoHS

For more information, please visit [Contact US](#)

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series
[120006](#) Series

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

[1200060592](#)