

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1200060594

Status:


Active

Overview:

Brad Micro-Change (M12) Connectors

Description:

Micro-Change (M12) Single-Ended Cordset, 4 Poles, Male (90°) to Pigtail, 0.34mm² PUR/PVC Cable 5.0m (16.40') Length

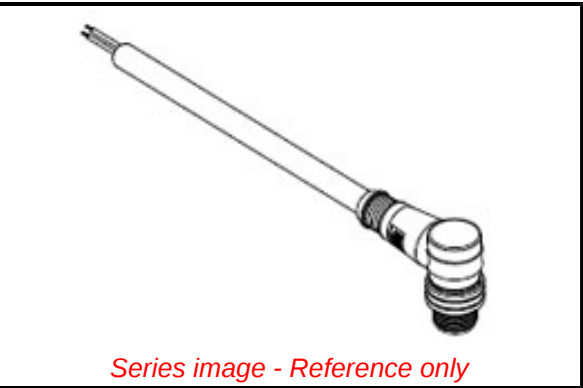

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Industrial Cordsets
Series	120006
Connector End A	Micro-Change (M12)
Connector End B	Pigtail
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	Brad Micro-Change (M12) Connectors
Product Name	Micro-Change (M12)
Protocol	N/A
Region	Europe
Type	Single Ended
UPC	883906068233
Physical	
Cable Diameter	5.30mm (.209")
Cable Length	5.0m (16.40')
Color - Cable Jacket	Black
Coupling Style	Threaded
Gender	Male-Pigtail
Keyway	Single
LED Indicator	No
Material - Cable Jacket	PUR/PVC
Material - Connector Body	PUR
Material - Coupling Nut	Nickel-plated Brass
Material - O-Ring	Fluoro-elastomer
Material - Plating Mating	Gold
Net Weight	180.501/g
Orientation	90° to Pigtail
Poles	4
Temperature Range - Operating	-20° to +80°C
Wire Size AWG	N/A
Wire/Cable Type	EU Cable
Electrical	
Current - Maximum per Contact	4.0A
Voltage - Maximum	250V AC/DC
Material Info	
Engineering Number	804007P03M050
Reference - Drawing Numbers	
Sales Drawing	1200659138-000

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Contained Per - D(2021)4569-DC (8 July 2021)	
Lead	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained
ZZCERT_CE - Declaration of Conformity	CER_4000380967_00_000.pdf

Search Parts in this Series

120006 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

[1200060594](#)