


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1200060697](#)
Status: **Active**
Overview: [Brad Micro-Change \(M12\) Connectors](#)
Description: Micro-Change (M12) Single-Ended Cordset, 5 Poles, Male (90°) to Pigtail, 0.34mm² PUR/PVC Cable 2.0m (6.56') Length

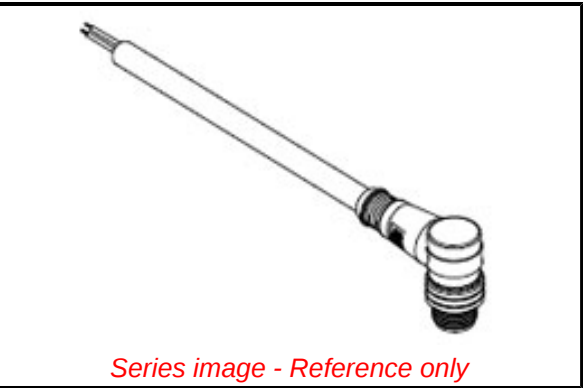

Documents:
[Drawing \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Industrial Cordsets
Series	120006
Connector End A	Micro-Change (M12)
Connector End B	Pigtail
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	Brad Micro-Change (M12) Connectors
Product Name	Micro-Change (M12)
Protocol	N/A
Region	Europe
Type	Single Ended
UPC	883906137410

Physical	
Cable Diameter	5.70mm (.224")
Cable Length	2.0m (6.56')
Color - Cable Jacket	Black
Coupling Style	Threaded
Gender	Male-Pigtail
Keyway	Single
LED Indicator	No
Material - Cable Jacket	PUR/PVC
Material - Connector Body	PUR
Material - Coupling Nut	Nickel-plated Brass
Material - O-Ring	Fluoro-elastomer
Material - Plating Mating	Gold
Orientation	90° to Pigtail
Poles	5
Temperature Range - Operating	-20° to +80°C
Wire Size AWG	N/A
Wire/Cable Type	EU Cable

Electrical	
Current - Maximum per Contact	4.0A
Voltage - Maximum	250V AC/DC

Material Info	
Engineering Number	805007P03M020

Reference - Drawing Numbers	
Sales Drawing	1200659138-000

EU ELV

Not Relevant

EU RoHS

**Compliant with
Exemption 6(c)**

REACH SVHC

Contained Per -
D(2020)9139-DC (19
Jan 2021)

Lead
Bisphenol-A

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained
ZZCERT_CE -	CER_4000380987_00_000.pdf
Declaration of Conformity	

Search Parts in this Series

[120006](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1200060697