

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1200650265

Status:

Active

Overview:


Brad Micro-Change (M12) Connectors

Description:

Micro-Change (M12) Single-Ended Cordset, 4 Poles, Female (Straight) to Pigtail, 22 AWG, PVC Cable, 5.0m (16.40') Length

Documents:	
Drawing (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR6837
UL	E152210
General	
Product Family	Industrial Cordsets
Series	120065
Connector End A	Micro-Change (M12)
Connector End B	Pigtail
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	Brad Micro-Change (M12) Connectors
Product Name	Micro-Change (M12)
Protocol	N/A
Region	America
Type	Single Ended
UPC	78172553162
Physical	
Cable Diameter	5.33mm (.210")
Cable Length	5.0m (16.40')
Color - Cable Jacket	Yellow
Coupling Style	Threaded
Gender	Female-Pigtail
Keyway	Single
LED Indicator	No
Material - Cable Jacket	PVC
Material - Connector Body	PUR
Material - Coupling Nut	Nickel-plated Brass
Material - O-Ring	Fluoro-elastomer
Material - Plating Mating	Gold
Net Weight	191.783/g
Orientation	Straight to Pigtail
Poles	4
Temperature Range - Operating	-20°C to +105°C
Wire Size AWG	22
Wire/Cable Type	UL 2661
Electrical	
Current - Maximum per Contact	4.0A
Voltage - Maximum	250V AC/DC
Material Info	
Engineering Number	804000A09M050
Reference - Drawing Numbers	
Sales Drawing	SD-120065-026-001

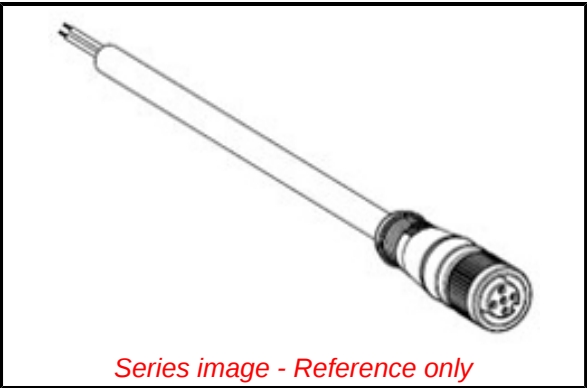

Series image - Reference only

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Contained Per - D(2020)9139-DC (19 Jan 2021)	
Lead	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

120065 Series

This document was generated on 09/15/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[120065-0265](#)