

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1200650470

Status:

Active

Overview:


Brad Micro-Change (M12) Connectors

Description:

Micro-Change (M12) Single-Ended Cordset, 5 Poles, Female (Straight) to Pigtail, 22 AWG, PVC Cable, 1.0m (3.28') Length

Documents:	
Drawing (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR6837
UL	E152210
General	
Product Family	Industrial Cordsets
Series	120065
Connector End A	Micro-Change (M12)
Connector End B	Pigtail
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	Brad Micro-Change (M12) Connectors
Product Name	Micro-Change (M12)
Protocol	N/A
Region	America
Type	Single Ended
UPC	78678883306
Physical	
Cable Diameter	5.72mm (.225")
Cable Length	1.0m (3.28')
Color - Cable Jacket	Yellow
Coupling Style	Threaded
Gender	Female-Pigtail
Keyway	Single
LED Indicator	No
Material - Cable Jacket	PVC
Material - Connector Body	PUR
Material - Coupling Nut	Nickel-plated Brass
Material - O-Ring	Fluoro-elastomer
Material - Plating Mating	Gold
Net Weight	188.000/g
Orientation	Straight to Pigtail
Poles	5
Temperature Range - Operating	-20° to +105°C
Wire Size AWG	22
Wire/Cable Type	UL 2661
Electrical	
Current - Maximum per Contact	4.0A
Voltage - Maximum	250V AC/DC
Material Info	
Engineering Number	805000A09M010
Reference - Drawing Numbers	
Sales Drawing	SD-120065-026-001

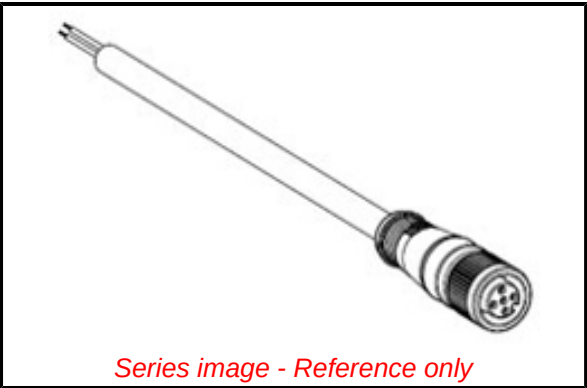

Series image - Reference only

EU ELV

Compliant with Exemption 3

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per - D(2021)4569-DC (8 July 2021)

Lead

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

Not Relevant

Compliant with Exemption 3

Not Contained

China RoHS

Search Parts in this Series

120065 Series

This document was generated on 01/18/2022

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

[1200650470](#)