

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1200650533

Status:


Active

Overview:

Brad Micro-Change (M12) Connectors

Description:

Micro-Change (M12) Single-Ended Cordset, 5 Poles, Male (Straight) to Pigtail, 22 AWG, Yellow PVC Cable, 10.0m (32.81') Length

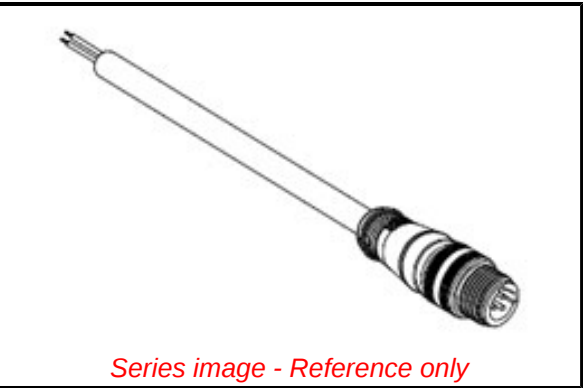

Series image - Reference only

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR6837
UL	E152210
General	
Product Family	Industrial Cordsets
Series	120065
Connector End A	Micro-Change (M12)
Connector End B	Pigtail
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	Brad Micro-Change (M12) Connectors
Product Name	Micro-Change (M12)
Protocol	N/A
Region	America
Type	Single Ended
UPC	78678845935
Physical	
Cable Diameter	5.72mm (.225")
Cable Length	10.0m (32.81')
Color - Cable Jacket	Yellow
Coupling Style	Threaded
Gender	Male-Pigtail
Keyway	Single
LED Indicator	No
Material - Cable Jacket	PVC
Material - Connector Body	PUR
Material - Coupling Nut	Nickel-plated Brass
Material - O-Ring	Fluoro-elastomer
Material - Plating Mating	Gold
Net Weight	899.000/g
Orientation	Straight to Pigtail
Poles	5
Temperature Range - Operating	-20° to +105°C
Wire Size AWG	22
Wire/Cable Type	UL 2661
Electrical	
Current - Maximum per Contact	4.0A
Voltage - Maximum	250V AC/DC
Material Info	
Engineering Number	805006A09M100
Reference - Drawing Numbers	
Sales Drawing	SD-120065-028-001

EU ELV

Compliant with
Exemption 3

EU RoHS

Compliant with
Exemption 6(c)

REACH SVHC

Contained Per -
D(2021)4569-DC (8
July 2021)
Lead

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

ELV

China RoHS

Not Relevant

Compliant with
Exemption 3

RoHS Phthalates

Not Contained

Search Parts in this Series

120065 Series

This document was generated on 01/18/2022

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1200650533