


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1200651425](#)
Status: **Active**
Overview: [Brad Micro-Push M12 Cordsets and Connectors](#)
Description: Micro-Push (M12) Single-Ended Cordset, 4 Poles, Female (90°)-to-Pigtail, 22 AWG, Unshielded PVC Cable, 2.0m (6.56') Length

Documents:	
Drawing (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
UL	E152210
General	
Product Family	Industrial Cordsets
Series	120065
Connector End A	Micro-Push (M12)
Connector End B	Pigtail
IP Rating	IP65
Material - Contact	Copper Alloy
Overview	Brad Micro-Push M12 Cordsets and Connectors
Product Name	Micro-Push
Protocol	N/A
Type	Single Ended
UPC	78678851099
Physical	
Cable Diameter	4.70mm (.185")
Cable Length	2.0m (6.56')
Color - Cable Jacket	Black
Coupling Style	Push to Lock
Gender	Female-Pigtail
Keyway	A-coded
LED Indicator	No
Material - Cable Jacket	PVC
Material - Connector Body	Nylon
Material - Coupling Nut	N/A
Material - Plating Mating	Gold
Orientation	90° to Pigtail
Poles	4
Temperature Range - Operating	-25°C to +105°C
Wire Size AWG	22
Wire/Cable Type	Unshielded PVC
Electrical	
Current - Maximum per Contact	4.0A
Voltage - Maximum	250V AC/DC
Material Info	
Engineering Number	N04001A41M020G
Reference - Drawing Numbers	
Sales Drawing	SD-120065-085-001

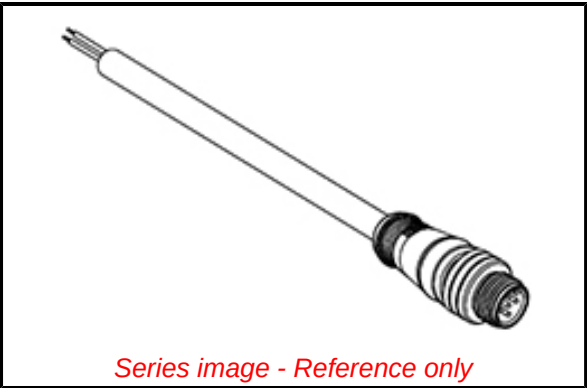

Series image - Reference only

EU ELV Compliant	
EU RoHS Compliant REACH SVHC Not Contained Per - D(2021)4569-DC (8 July 2021) Halogen-Free Status Not Relevant	China RoHS
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series 120065 Series
Mates With Micro-Change M12 Connectors

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[120065-1425](#)