

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1200651493

Status:

Active

Overview:


Brad Micro-Change (M12) Connectors

Description:

Micro-Change (M12) Single-Ended Cordset, 3 Poles, Female (90°) to Pigtail, 22 AWG, Yellow TPE Cable, 10.0m (32.81') Length

Documents:	
Drawing (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR6837
UL	E152210
General	
Product Family	Industrial Cordsets
Series	120065
Connector End A	Micro-Change (M12)
Connector End B	Pigtail
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	Brad Micro-Change (M12) Connectors
Product Name	Micro-Change (M12)
Protocol	N/A
Region	America
Type	Single Ended
UPC	78678885432
Physical	
Cable Diameter	5.00mm (.197")
Cable Length	10.0m (32.81')
Color - Cable Jacket	Yellow
Coupling Style	Threaded
Gender	Female-Pigtail
Keyway	Single
LED Indicator	No
Material - Cable Jacket	TPE
Material - Connector Body	TPE
Material - Coupling Nut	Nickel-plated Brass
Material - O-Ring	Fluoro-elastomer
Material - Plating Mating	Gold
Net Weight	888.000/g
Orientation	90° to Pigtail
Poles	3
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	22
Wire/Cable Type	PLTC/ITC
Electrical	
Current - Maximum per Contact	4.0A
Voltage - Maximum	250V AC/DC
Material Info	
Engineering Number	803001K05M100
Reference - Drawing Numbers	
Sales Drawing	SD-120065-113-001

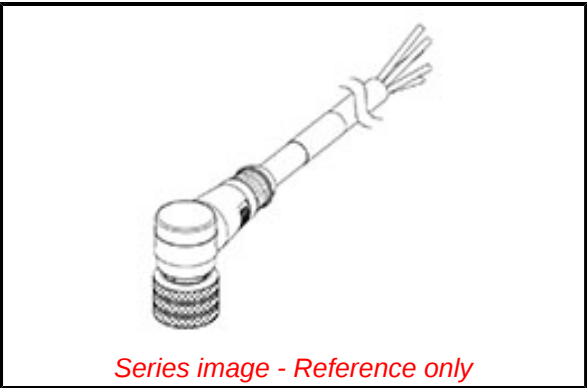

EU ELV	
Compliant with Exemption 3	
EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Contained Per - D(2021)4569-DC (8 July 2021)	
Lead	
Halogen-Free	
Status	
Not Relevant	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Compliant with Exemption 3
RoHS Phthalates	Not Contained

Search Parts in this Series

120065 Series

This document was generated on 01/17/2022

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1200651493