

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1200651720

Status:


Active

Overview:

Brad Micro-Change (M12) Connectors

Description:

Micro-Change (M12) Single-Ended Cordset, 5 Poles, Female (90°) to Pigtail, 18 AWG, TPE Cable, 2.0m (6.56') Length

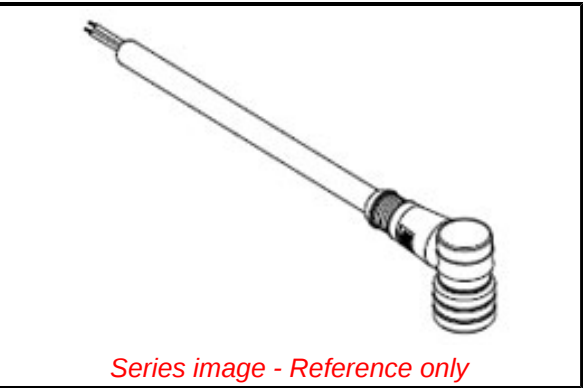

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR6837
UL	E152210
General	
Product Family	Industrial Cordsets
Series	120065
Connector End A	Micro-Change (M12)
Connector End B	Pigtail
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	Brad Micro-Change (M12) Connectors
Product Name	Micro-Change (M12)
Protocol	N/A
Region	America
Type	Single Ended
UPC	78678883821
Physical	
Cable Diameter	6.86mm (.270")
Cable Length	2.0m (6.56')
Color - Cable Jacket	Yellow
Coupling Style	Threaded
Gender	Female-Pigtail
Keyway	Single
LED Indicator	No
Material - Cable Jacket	TPE
Material - Connector Body	TPE
Material - Coupling Nut	Nickel-plated Brass
Material - O-Ring	Fluoro-elastomer
Material - Plating Mating	Gold
Net Weight	169.500/g
Orientation	90° to Pigtail
Poles	5
Temperature Range - Operating	-20°C to +105°C
Wire Size AWG	18
Wire/Cable Type	PLTC/ITC
Electrical	
Current - Maximum per Contact	4.0A
Voltage - Maximum	250V AC/DC
Material Info	
Engineering Number	805001K03M020
Reference - Drawing Numbers	
Sales Drawing	1200658471-000

EU ELV	
Compliant with Exemption 3	
EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Contained Per - D(2020)9139-DC (19 Jan 2021)	
Lead	
Halogen-Free	
Status	
Not Relevant	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Compliant with Exemption 3
RoHS Phthalates	Not Contained

Search Parts in this Series

120065 Series

This document was generated on 10/06/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1200651720