

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1200661713](#)
Status: **Active**
Overview: [Brad Micro-Change \(M12\) Connectors](#)
Description: Micro-Change (M12) Double-Ended Cordset, 4 Poles, Male (Straight) to USB, PUR Cable, 2.0m (6.56') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Industrial Cordsets
Series	120066
Connector End A	Micro-Change (M12)
Connector End B	USB
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	Brad Micro-Change (M12) Connectors
Product Name	Micro-Change (M12)
Region	Europe
Type	Double Ended
UPC	78172512510

Physical

Cable Diameter	4.70mm (.185")
Cable Length	2.0m (6.56')
Color - Cable Jacket	Black
Coupling Style	Threaded
Gender	Male-Male
Keyway	N/A
LED Indicator	No
Material - Cable Jacket	PUR
Material - Connector Body	PUR
Material - Coupling Nut	Nickel-plated Brass
Material - O-Ring	Fluoro-elastomer
Material - Plating Mating	Gold
Net Weight	1.000/g
Orientation	Straight to Straight
Poles	5
Temperature Range - Operating	-40°C to +105°C
Wire Size AWG	N/A
Wire/Cable Type	N/A


Electrical

Current - Maximum per Contact	Contact Molex
Voltage - Maximum	30V AC/DC

Material Info

Reference - Drawing Numbers

Sales Drawing	1200661713-000, SD-120066-1713-001
---------------	------------------------------------

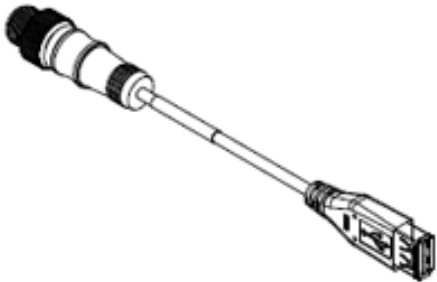

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

**Compliant with
Exemption 6(c)**

REACH SVHC

Contained Per -
D(2020)9139-DC (19
Jan 2021)

Lead

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China RoHS

China ROHS	Not Relevant
ELV	Not Reviewed
RoHS Phthalates	Not Contained

Search Parts in this Series

[120066](#) Series

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1200661713