

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1200665461](#)
Status: **Active**
Overview: Brad Passive-Signal and Safety MPIS Boxes
Description: Brad Safety Micro-Change (M12) Double-Ended Cordset, 8 Poles, Female (Straight) to Male (Straight), 0.25mm² WSOR Cable, 1.0m (3.28') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Datasheet \(PDF\)](#)

General

Product Family	Industrial Cordsets
Series	120066
Connector End A	Micro-Change (M12)
Connector End B	Micro-Change (M12)
IP Rating	IP67
Material - Contact	Brass
Overview	Brad Passive-Signal and Safety MPIS Boxes
Product Name	Brad Safety, Micro-Change (M12)
Type	Double Ended
UPC	889056562041

Physical

Cable Diameter	6.40mm (.252")
Cable Length	1.0m (3.28')
Color - Cable Jacket	Black
Coupling Style	Threaded
Gender	Female-Male
Keyway	A-coded
LED Indicator	No
Material - Cable Jacket	PUR
Material - Connector Body	TPU
Material - Coupling Nut	Nickel-plated Brass
Material - Plating Mating	Gold
Net Weight	78.504/g
Orientation	Straight to Straight
Poles	8
Temperature Range - Operating	-40°C to +90°C
Wire Size AWG	24
Wire/Cable Type	WSOR

Electrical


Current - Maximum per Contact	2.0A
Voltage - Maximum	30V AC/DC

Material Info

Engineering Number	888030B41M010R
--------------------	----------------

Reference - Drawing Numbers

Sales Drawing	1200668993-000
---------------	----------------

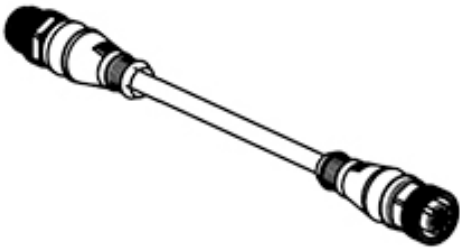

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

**Compliant with
Exemption 6(c)**

REACH SVHC

Contained Per -
D(2020)9139-DC (19
Jan 2021)

Lead

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

50 Image

Not Relevant

Not Contained

Search Parts in this Series

[120066](#) Series

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

120066-5461