

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1200720551](#)
Status: **Active**
Overview: [Brad Micro-Change \(M12\) Connectors](#)
Description: Micro-Change (1/2"-20 UNF) Single-Ended Cordset, 5 Poles, Male (Straight) to Pigtail, 22 AWG, PVC Cable, 1.83m (6.0') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837
UL E152210

General

Product Family Industrial Cordsets
Series [120072](#)
Connector End A Micro-Change (1/2" - 20 UNF)
Connector End B Pigtail
IP Rating IP67
Material - Contact Copper Alloy
Overview [Brad Micro-Change \(M12\) Connectors](#)
Product Name Micro-Change (1/2" - 20 UNF)
Protocol PROFIBUS
Region America
Type Single Ended
UPC 78678829597

Physical

Cable Diameter 5.80mm (.230")
Cable Length 1.83m (6.0')
Color - Cable Jacket Yellow
Coupling Style Threaded
Gender Male-Pigtail
Keyway Dual
LED Indicator No
Material - Cable Jacket PVC
Material - Connector Body PVC
Material - Coupling Nut Black Epoxy Coated Zinc
Material - O-Ring Nitrile Rubber
Material - Plating Mating Gold
Net Weight 121.562/g
Orientation Straight to Pigtail
Poles 5
Temperature Range - Operating -20°C to +105°C
Wire Size AWG 22
Wire/Cable Type UL 2661

Electrical


Current - Maximum per Contact 4.0A
Voltage - Maximum 250V AC/DC

Material Info

Engineering Number 705006D02F060

Reference - Drawing Numbers

Sales Drawing SD-120072-007

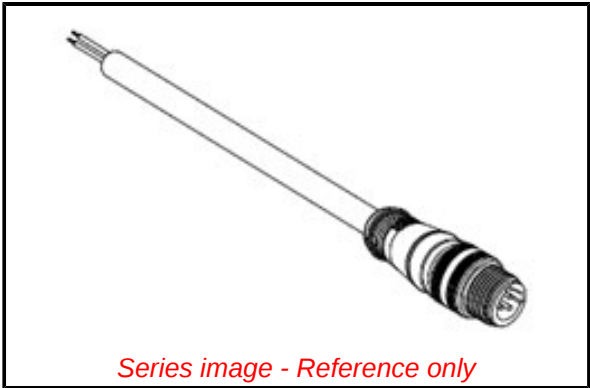

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

[120072 Series](#)

This document was generated on 07/30/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1200720551](#)