

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1200860579

Status:


Active

Overview:

Brad Nano-Change (M8) Products

Description:

Nano-Change (M8) Single-Ended Cordset, 5 Poles, Male (Straight) to Pigtail, 24 AWG, Yellow PVC Cable, 10.0m (32.81') Length

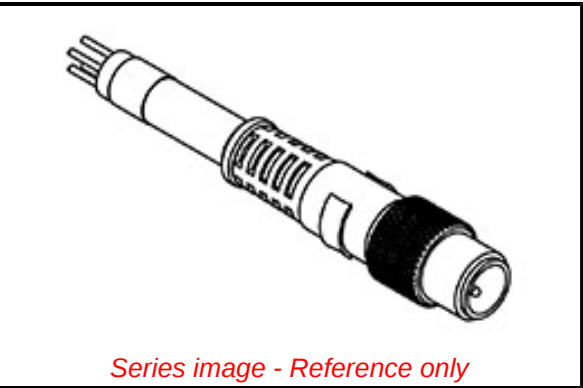

Documents:	
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
Agency Certification	
CSA	LR6837
UL	E152210
General	
Product Family	Industrial Cordsets
Series	120086
Connector End A	Nano-Change (M8)
Connector End B	Pigtail
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	Brad Nano-Change (M8) Products
Product Name	Nano-Change (M8)
Region	America
Type	Single Ended
UPC	78172505819
Physical	
Cable Diameter	5.08mm (.200")
Cable Length	10.0m (32.81')
Color - Cable Jacket	Yellow
Coupling Style	Threaded
Gender	Male-Pigtail
Keyway	B-coded
LED Indicator	No
Material - Cable Jacket	PVC
Material - Connector Body	TPE
Material - Coupling Nut	Nickel-plated Brass
Material - Plating Mating	Gold
Net Weight	1545.000/g
Orientation	Straight to Pigtail
Poles	5
Temperature Range - Operating	-20° to +105°C
Wire Size AWG	24
Wire/Cable Type	UL 2661
Electrical	
Current - Maximum per Contact	3.0A
Voltage - Maximum	60V AC / 75V DC
Material Info	
Engineering Number	405006A10M100
Reference - Drawing Numbers	
Sales Drawing	SD-120086-132-001

EU ELV

Not Reviewed

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per - D(2021)4569-DC (8 July 2021)

Lead

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Reviewed

RoHS Phthalates

Not Contained

Search Parts in this Series

120086 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1200860579