

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1200910025](#)
Status: **Active**
Overview: [Brad Nano-Change \(M8\) Products](#)
Description: Nano-Change (M8) Field Attachable Connector, 4 Poles, Straight, Male, Unshielded, Screw Termination, Cable Diameter 3.50-5.00mm

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)


General
Product Family Field Attachable / Accessories
Series [120091](#)
Approvals cCSAus certified
IP Rating IP67
Material - Contact Brass
Overview [Brad Nano-Change \(M8\) Products](#)
Product Name Nano-Change (M8)
Type Field Attachable Connector
UPC 889056411950

Physical
Cable Diameter 3.50-5.00mm (.138-.197")
Coupling Type External Thread
Diagnostics / LEDs No
Diagnostics Port No
Gender Male
Keyway None
Material - Connector Body PA
Material - Coupling Nut Zinc Die-Cast, Nickel-Plated
Material - Plating Mating Gold
Net Weight 8.969/g
Orientation Straight
Poles 4
Temperature Range - Operating -40°C to +85°C
Wire Size AWG 20-26

Electrical
Current - Maximum per Contact 4.0A
Voltage - Maximum 30V

Material Info
Engineering Number N04MA03134

Reference - Drawing Numbers
Sales Drawing 1200910025-000

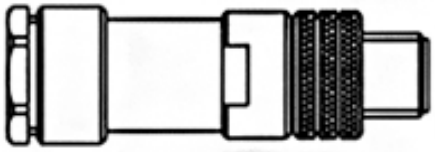

Series image - Reference only

EU ELV
Not Relevant

EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Not Contained Per - ED/21/2016 (20 June 2016)	
Halogen-Free Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[120091](#) Series

Mates With
[1200910026](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1200910025](#)