

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1201030001

Status:


Active

Overview:

PROFIBUS Solutions

Description:

PROFIBUS Attachable D-Sub Connector with Diagnostics LEDs and Programming Port, 90° Angle

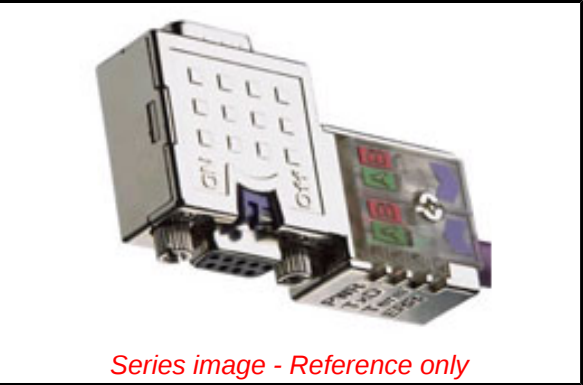

Series image - Reference only

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General

Product Family

Series

IP Rating

Material - Contact

Overview

Product Name

Type

UPC

Field Attachable / Accessories

120103

IP67

N/A

PROFIBUS Solutions

D-Sub, PROFIBUS

Field Attachable Connector

78678853530

Physical

Cable Diameter

Coupling Type

Diagnostics / LEDs

Diagnostics Port

Gender

Keyway

Material - Connector Body

Material - Coupling Nut

Material - Plating Mating

Net Weight

Orientation

Poles

Temperature Range - Operating

Wire Size AWG

N/A

N/A

Yes

Yes

N/A

None

Die-Cast Zinc

N/A

n/a

90.000/g

90° Angle

N/A

-20°C to +80°C

N/A

Electrical

Current - Maximum per Contact

Voltage - Maximum

4.0A

30V

Material Info

Engineering Number

PA9D01-42

Reference - Drawing Numbers

Sales Drawing

SD-120103-003-001

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/30/2017 (7 July
2017)

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

ZZCERT_CE -

Declaration of

Conformity

China RoHS

Green Image

Not Relevant

Not Contained

CER_4000380995_00_000.pdf

Search Parts in this Series

120103 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1201030007