

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1201080289

Status:


Active

Overview:

Brad Industrial Ethernet Solutions

Description:

Micro-Change (M12) to Standard RJ-45 Double-Ended Cordset, 4 Poles, Male (Straight) to Male (Straight), 22 AWG, Shielded PUR Cable, 4.0m (13.12') Length, 6.70mm (.264") Diameter, Green

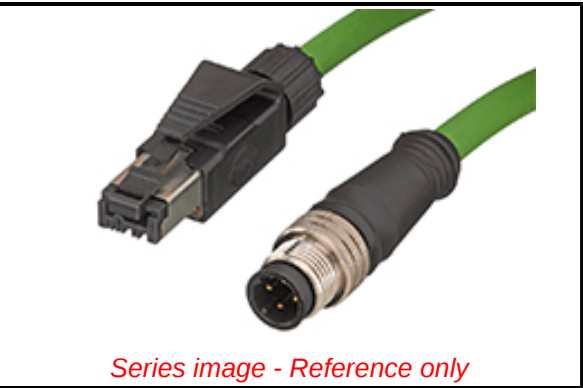

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
UL	E361772
General	
Product Family	Industrial Cordsets
Series	120108
Connector End A	Micro-Change (M12)
Connector End B	RJ-45 (standard)
IP Rating	IP67 (M12 only)
Material - Contact	Copper Alloy
Overview	Brad Industrial Ethernet Solutions
Performance Category	5e
Product Name	Industrial Ethernet, Micro-Change (M12)
Protocol	N/A
Type	Double Ended
UPC	78172538073
Physical	
Cable Diameter	6.70mm (.264")
Cable Length	4.0m (13.12')
Color - Cable Jacket	Green
Coupling Style	Threaded
Gender	Male-Male
Keyway	D-coded
LED Indicator	No
Material - Cable Jacket	PUR
Material - Connector Body	PUR, Thermoplastic
Material - Coupling Nut	Nickel-plated Brass
Material - Plating Mating	Gold
Net Weight	279.866/g
Orientation	Straight to Straight
Poles	4
Temperature Range - Operating	-20° to +60°C
Wire Size AWG	22
Wire/Cable Type	Shielded PUR
Electrical	
Current - Maximum per Contact	1.5A
Voltage - Maximum	30V
Material Info	
Engineering Number	E16A06011M040
Reference - Drawing Numbers	
Sales Drawing	1201080256-000

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Contained Per -ED/01/2018 (15 January 2018)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

120108 Series

This document was generated on 12/23/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1201080289](#)