

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1201080290

Status:


Active

Overview:

Brad Industrial Ethernet Solutions

Description:

Micro-Change (M12) to Standard RJ-45 Double-Ended Cordset, 4 Poles, Male (Straight) to Male (Straight), 22 AWG, Shielded PUR Cable, 9.0m (29.53') Length, 6.70mm (.264") Diameter, Green

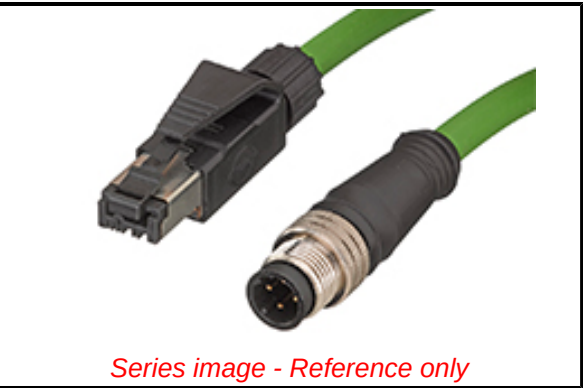

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
UL	E361772
General	
Product Family	Industrial Cordsets
Series	120108
Connector End A	Micro-Change (M12)
Connector End B	RJ-45 (standard)
IP Rating	IP67 (M12 only)
Material - Contact	Copper Alloy
Overview	Brad Industrial Ethernet Solutions
Performance Category	5e
Product Name	Industrial Ethernet, Micro-Change (M12)
Protocol	N/A
Type	Double Ended
UPC	78172538090
Physical	
Cable Diameter	6.70mm (.264")
Cable Length	9.0m (29.53')
Color - Cable Jacket	Green
Coupling Style	Threaded
Gender	Male-Male
Keyway	D-coded
LED Indicator	No
Material - Cable Jacket	PUR
Material - Connector Body	PUR, Thermoplastic
Material - Coupling Nut	Nickel-plated Brass
Material - Plating Mating	Gold
Orientation	Straight to Straight
Poles	4
Temperature Range - Operating	-20° to +60°C
Wire Size AWG	22
Wire/Cable Type	Shielded PUR
Electrical	
Current - Maximum per Contact	1.5A
Voltage - Maximum	30V
Material Info	
Engineering Number	E16A06011M090
Reference - Drawing Numbers	
Sales Drawing	1201080256-000

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Contained Per -ED/01/2018 (15 January 2018)

Halogen-Free

Status

Low-Halogen

For more information, please visit

Contact US

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

120108 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1201080290](#)