

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1201080291](#)
Status: **Active**
Overview: [Brad Industrial Ethernet Solutions](#)
Description: Micro-Change (M12) to Standard RJ-45 Double-Ended Cordset, 4 Poles, Male (Straight) to Male (Straight), 22 AWG, Shielded PUR Cable, 12.0m (39.37') Length, 6.70mm (.264") Diameter, Green

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E361772

General

Product Family Industrial Cordsets
Series [120108](#)
Connector End A Micro-Change (M12)
Connector End B RJ-45 (standard)
IP Rating IP67 (M12 only)
Material - Contact Copper Alloy
Overview [Brad Industrial Ethernet Solutions](#)
Performance Category 5e
Product Name Industrial Ethernet, Micro-Change (M12)
Protocol N/A
Type Double Ended
UPC 78172538074

Physical

Cable Diameter 6.70mm (.264")
Cable Length 12.0m (39.37")
Color - Cable Jacket Green
Coupling Style Threaded
Gender Male-Male
Keyway D-coded
LED Indicator No
Material - Cable Jacket PUR
Material - Connector Body PUR, Thermoplastic
Material - Coupling Nut Nickel-plated Brass
Material - Plating Mating Gold
Orientation Straight to Straight
Poles 4
Temperature Range - Operating -20° to +60°C
Wire Size AWG 22
Wire/Cable Type Shielded PUR

Electrical


Current - Maximum per Contact 1.5A
Voltage - Maximum 30V

Material Info

Engineering Number E16A06011M120

Reference - Drawing Numbers

Sales Drawing 1201080256-000

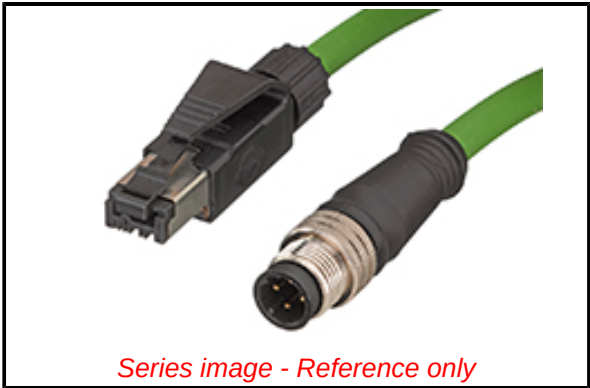

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Contained Per
-ED/01/2018 (15
January 2018)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[120108](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1201080291