

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1201080293

Status:


Active

Overview:

Brad Industrial Ethernet Solutions

Description:

Micro-Change (M12) to Standard RJ-45 Double-Ended Cordset, 4 Poles, Male (Straight) to Male (Straight), 22 AWG, Shielded PUR Cable, 18.0m (59.05' ) Length, 6.70mm (.264") Diameter, Green

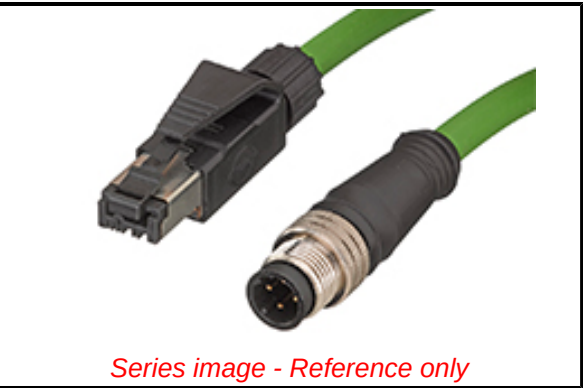

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

|                               |                                         |
|-------------------------------|-----------------------------------------|
| Agency Certification          |                                         |
| UL                            | E361772                                 |
| General                       |                                         |
| Product Family                | Industrial Cordsets                     |
| Series                        | 120108                                  |
| Connector End A               | Micro-Change (M12)                      |
| Connector End B               | RJ-45 (standard)                        |
| IP Rating                     | IP67 (M12 only)                         |
| Material - Contact            | Copper Alloy                            |
| Overview                      | Brad Industrial Ethernet Solutions      |
| Performance Category          | 5e                                      |
| Product Name                  | Industrial Ethernet, Micro-Change (M12) |
| Protocol                      | N/A                                     |
| Type                          | Double Ended                            |
| UPC                           | 78172538076                             |
| Physical                      |                                         |
| Cable Diameter                | 6.70mm (.264")                          |
| Cable Length                  | 18.0m (59.05')                          |
| Color - Cable Jacket          | Green                                   |
| Coupling Style                | Threaded                                |
| Gender                        | Male-Male                               |
| Keyway                        | D-coded                                 |
| LED Indicator                 | No                                      |
| Material - Cable Jacket       | PUR                                     |
| Material - Connector Body     | PUR, Thermoplastic                      |
| Material - Coupling Nut       | Nickel-plated Brass                     |
| Material - Plating Mating     | Gold                                    |
| Net Weight                    | 7003.803/g                              |
| Orientation                   | Straight to Straight                    |
| Poles                         | 4                                       |
| Temperature Range - Operating | -20° to +60°C                           |
| Wire Size AWG                 | 22                                      |
| Wire/Cable Type               | Shielded PUR                            |
| Electrical                    |                                         |
| Current - Maximum per Contact | 1.5A                                    |
| Voltage - Maximum             | 30V                                     |
| Material Info                 |                                         |
| Engineering Number            | E16A06011M180                           |
| Reference - Drawing Numbers   |                                         |
| Sales Drawing                 | 1201080256-000                          |

|                                                               |               |
|---------------------------------------------------------------|---------------|
| EU ELV                                                        |               |
| Not Relevant                                                  |               |
| EU RoHS                                                       | China RoHS    |
| Compliant with Exemption 6(c)                                 |               |
| REACH SVHC                                                    |               |
| Not Contained Per -ED/01/2018 (15 January 2018)               |               |
| Halogen-Free                                                  |               |
| Status                                                        |               |
| Not Low-Halogen                                               |               |
| For more information, please visit <a href="#">Contact US</a> |               |
| China ROHS                                                    | 50 Image      |
| ELV                                                           | Not Relevant  |
| RoHS Phthalates                                               | Not Contained |

Search Parts in this Series

120108 Series

This document was generated on 01/07/2022

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1201080293](#)