

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1201080294

Status:


Active

Overview:

Brad Industrial Ethernet Solutions

Description:

Micro-Change (M12) to Standard RJ-45 Double-Ended Cordset, 4 Poles, Male (Straight) to Male (Straight), 22 AWG, Shielded PUR Cable, 70.0m (229.66') Length, 6.70mm (.264") Diameter, Green

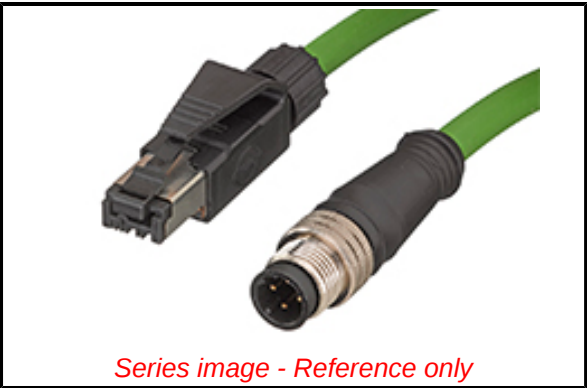

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification		
UL		E361772
General		
Product Family		Industrial Cordsets
Series		120108
Connector End A		Micro-Change (M12)
Connector End B		RJ-45 (standard)
IP Rating		IP67 (M12 only)
Material - Contact		Copper Alloy
Overview		Brad Industrial Ethernet Solutions
Performance Category		5e
Product Name		Industrial Ethernet, Micro-Change (M12)
Protocol		N/A
Type		Double Ended
UPC		78172538465
Physical		
Cable Diameter		6.70mm (.264")
Cable Length		70.0m (229.66')
Color - Cable Jacket		Green
Coupling Style		Threaded
Gender		Male-Male
Keyway		D-coded
LED Indicator		No
Material - Cable Jacket		PUR
Material - Connector Body		PUR, Thermoplastic
Material - Coupling Nut		Nickel-plated Brass
Material - Plating Mating		Gold
Orientation		Straight to Straight
Poles		4
Temperature Range - Operating		-20° to +60°C
Wire Size AWG		22
Wire/Cable Type		Shielded PUR
Electrical		
Current - Maximum per Contact		1.5A
Voltage - Maximum		30V
Material Info		
Engineering Number		E16A06011M700
Reference - Drawing Numbers		
Sales Drawing		1201080256-000

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Contained Per -ED/01/2018 (15 January 2018)

Halogen-Free

Status

Low-Halogen

For more information, please visit

Contact US

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

120108 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1201080294