

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1201080315

Status:

Active

Overview:

Brad Industrial Ethernet Solutions

Description:

Double-Ended RJ-45 Cordset, 4 Poles, Male (Straight) to Male (Straight), 26 AWG, Shielded TPE Cable, 15.0m (49.21') Length, 6.00mm (.236") Diameter, Teal

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

UL

E361772

General

Product Family

Industrial Cordsets

Series

120108

Connector End A

RJ-45 (standard)

Connector End B

RJ-45 (standard)

IP Rating

IP20

Material - Contact

Copper Alloy

Overview

Brad Industrial Ethernet Solutions

Performance Category

5e

Product Name

Industrial Ethernet

Protocol

N/A

Type

Double Ended

UPC

78172541630

Physical

Cable Diameter

6.00mm (.236")

Cable Length

15.0m (49.21')

Color - Cable Jacket

Teal

Coupling Style

N/A

Gender

Male-Male

Keyway

N/A

LED Indicator

No

Material - Cable Jacket

TPE

Material - Connector Body

PVC

Material - Coupling Nut

N/A

Material - Plating Mating

Gold

Orientation

Straight to Straight

Poles

4

Temperature Range - Operating

-20° to +75°C

Wire Size AWG

26

Wire/Cable Type

Shielded TPE

Electrical

Current - Maximum per Contact

1.5A

Voltage - Maximum

30V

Material Info


Engineering Number

E66A06005M150

Reference - Drawing Numbers

Sales Drawing

SD-120108-079-001

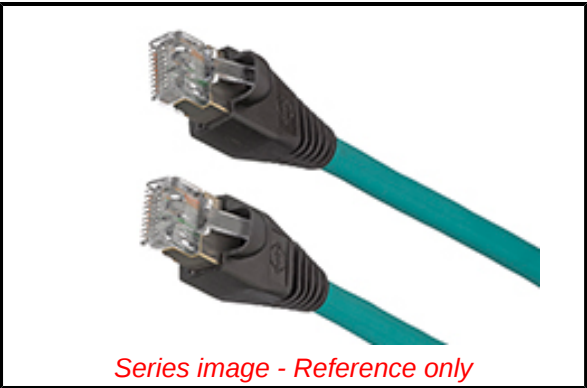

EU ELV

Not Relevant

EU RoHS

China RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit

Contact US

China ROHS

Not Reviewed

ELV

Not Relevant

RoHS Phthalates

Not Relevant

Search Parts in this Series

120108 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1201080315