

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1201080316

Status:

Active

Overview:

Brad Industrial Ethernet Solutions

Description:


Double-Ended RJ-45 Cordset, 4 Poles, Male (Straight) to Male (Straight), 26 AWG, Shielded TPE Cable, 30.0m (98.40') Length, 6.00mm (.236") Diameter, Teal

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
UL	E361772
General	
Product Family	Industrial Cordsets
Series	120108
Connector End A	RJ-45 (standard)
Connector End B	RJ-45 (standard)
IP Rating	IP20
Material - Contact	Copper Alloy
Overview	Brad Industrial Ethernet Solutions
Performance Category	5e
Product Name	Industrial Ethernet
Protocol	N/A
Type	Double Ended
UPC	78172541631
Physical	
Cable Diameter	6.00mm (.236")
Cable Length	30.0m (98.40')
Color - Cable Jacket	Teal
Coupling Style	N/A
Gender	Male-Male
Keyway	N/A
LED Indicator	No
Material - Cable Jacket	TPE
Material - Connector Body	PVC
Material - Coupling Nut	N/A
Material - Plating Mating	Gold
Orientation	Straight to Straight
Poles	4
Temperature Range - Operating	-20° to +75°C
Wire Size AWG	26
Wire/Cable Type	Shielded TPE
Electrical	
Current - Maximum per Contact	1.5A
Voltage - Maximum	30V
Material Info	
Engineering Number	E66A06005M300
Reference - Drawing Numbers	
Sales Drawing	SD-120108-079-001

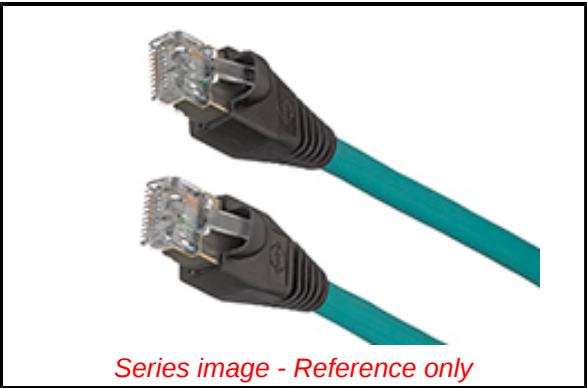

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

120108 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1201080316