

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1201095003

Status:


Active

Overview:

Brad Industrial Ethernet Solutions

Description:

Ultra-Lock (M12) Ethernet Receptacle, FPM PG9, Female (Straight), Panel Mount
6.00mm Pins, 4 Poles, D-Code

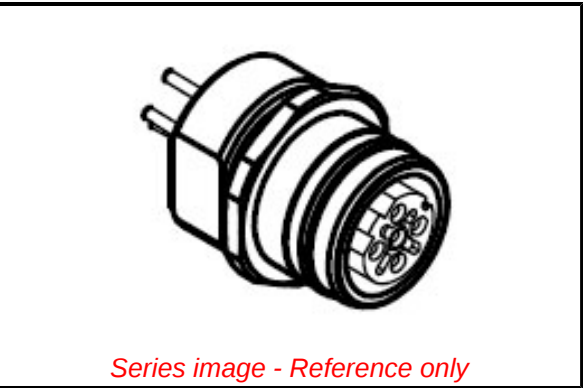

Series image - Reference only

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Industrial Receptacles
Series	120109
IP Rating	IP67
NEMA Rating	NEMA 6
Overview	Brad Industrial Ethernet Solutions
Product Name	Ultra-Lock (M12)
Type	PCB Mount
UPC	883906436841
Physical	
Coupling Type	Internal Thread
Gender	Female
Keyway	D-coded
Length	N/A
Material - Component	Nickel-plated Brass
Mounting Thread Size	M16
Net Weight	15.139/g
Orientation	Straight
Panel Mount	Front
Poles	4
Temperature Range - Operating	-25° to +90°C
Wire Size AWG	N/A
Wire/Cable Type	N/A
Electrical	
Current - Maximum per Contact	1.5A
Voltage - Maximum	125V
Material Info	
Engineering Number	ERWD2J30
Reference - Drawing Numbers	
Sales Drawing	SD-120109-005-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Contained Per - D(2021)4569-DC (8 July 2021)	
Lead	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

120109 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[120109-5003](#)