

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1210360192](#)
Status: **Active**
Overview: [mPm DIN Valve Connectors](#)
Description: Micro-Change (M12) to Brad mPm DIN Form A - 18mm Cordset, 5 Poles, Male (Straight) to Male (90°), 0.60m (1.97') Length, 24V

Documents:
[Drawing \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)


General	
Product Family	Industrial Cordsets
Series	121036
Connector End A	Brad mPm DIN A - 18mm
Connector End B	Micro-Change (M12)
IP Rating	IP65
Material - Contact	Copper Alloy
Overview	mPm DIN Valve Connectors
Product Name	Micro-Change (M12), mPm
Protocol	N/A
Region	America, Europe
Type	Double Ended
UPC	78678845415

Physical	
Cable Diameter	5.72mm (.225")
Cable Length	0.60m (1.97')
Color - Cable Jacket	Black
Coupling Style	Threaded
Gender	Male-Male
Keyway	Single
LED Indicator	No
Material - Cable Jacket	PUR
Material - Connector Body	Polypropylene
Material - Coupling Nut	Nickel-plated Brass
Material - Plating Mating	Gold
Net Weight	40.700/g
Orientation	90° to Straight
Poles	5
Temperature Range - Operating	-25°C to +75°C
Wire Size AWG	20
Wire/Cable Type	PUR

Electrical	
Current - Maximum per Contact	4.0A
Voltage - Maximum	24V

Material Info	
Engineering Number	E850B0P12M006

Reference - Drawing Numbers	
Sales Drawing	SD-121036-001-001

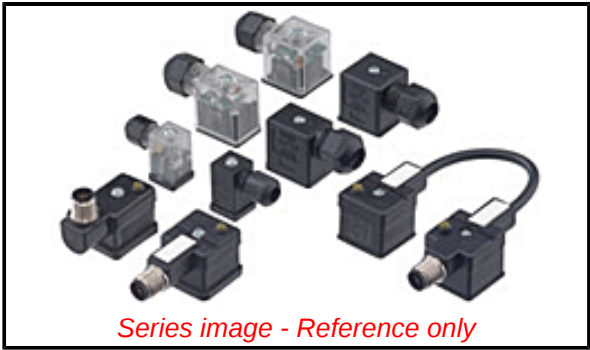

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

**Compliant with
Exemption 6(c)**

REACH SVHC

Contained Per -
D(2020)9139-DC (19
Jan 2021)
Lead

**Halogen-Free
Status**

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[121036](#) Series

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

[1210360192](#)