

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1210640871](#)
Status: **Active**
Overview: [mPm DIN Valve Connectors](#)
Description: mPm DIN Valve Connector, Form C-Micro 9.4mm, PG7 Internal Threads, 2 Pole Plus Ground with C4 Circuit, 24V, Yellow LED, Transparent, Nitrile Gasket, Bulk Pack Mounted

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Packaging Specification PK-121065-S19-001 \(PDF\)](#)

General

Product Family	Field Attachable / Accessories
Series	121064
Form	C - Micro 9.4mm
IP Rating	IP65, IP67
Material - Contact	Brass
Overview	mPm DIN Valve Connectors
Product Name	mPm
Type	Field Attachable Connector
UPC	883906736996

Physical

Cable Diameter	N/A
Coupling Type	Internal Thread
Diagnostics / LEDs	Yes
Diagnostics Port	No
Gender	N/A
Keyway	None
Material - Connector Body	Polypropylene
Material - Coupling Nut	N/A
Material - Plating Mating	Silver
Net Weight	9.749/g
Orientation	90° Angle
Pitch - Mating Interface	9.40mm
Poles	2
Temperature Range - Operating	-40°C to +90°C
Wire Size AWG	N/A

Electrical


Current - Maximum per Contact	16.0A
Voltage - Maximum	24V

Material Info

Engineering Number	S19207TC4H1
--------------------	-------------

Reference - Drawing Numbers

Packaging Specification	PK-121065-S19-001
Sales Drawing	SD-121064-003

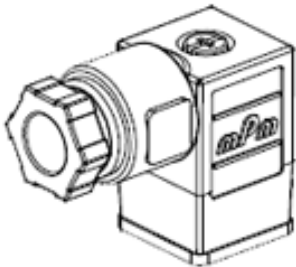

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Contained Per -
ED/71/2019 (16 July
2019)
lead

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[121064](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

[1210640871](#)