

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1210641239

Status:

Active

Overview:

mPm DIN Valve Connectors

Description:

mPm DIN Valve Connector, Form B, PG7 Internal Threads, 2 Pole Plus Ground with C4 Circuit, 24V, Yellow LED, Transparent, Nitrile Gasket, Bulk Pack Mounted


Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Packaging Specification PK-121064-S62-001 (PDF)

Agency Certification	
UL	E218123
General	
Product Family	Field Attachable / Accessories
Series	121064
IP Rating	IP65, IP67
Material - Contact	Brass
Overview	mPm DIN Valve Connectors
Product Name	mPm
Type	Field Attachable Connector
UPC	883906737832
Physical	
Cable Diameter	N/A
Coupling Type	Internal Thread
Diagnostics / LEDs	Yes
Diagnostics Port	No
Gender	N/A
Keyway	None
Material - Connector Body	Polypropylene
Material - Coupling Nut	N/A
Material - Plating Mating	Silver
Net Weight	18.860/g
Orientation	90° Angle
Pitch - Mating Interface	10.00mm
Poles	2
Temperature Range - Operating	-40°C to +90°C
Wire Size AWG	N/A
Electrical	
Current - Maximum per Contact	16.0A
Voltage - Maximum	24V
Material Info	
Engineering Number	S62209TC4H1
Reference - Drawing Numbers	
Packaging Specification	PK-121064-S62-001
Sales Drawing	SD-121064-004

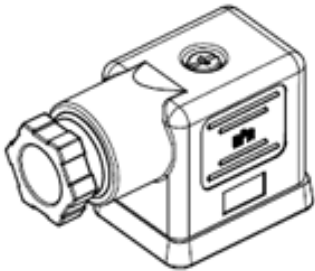

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Contained Per - ED/71/2019 (16 July 2019)

Lead

Halogen-Free

Status

Low-Halogen

For more information, please visit

Contact US

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

121064 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

[1210641239](#)