


NOTE 2

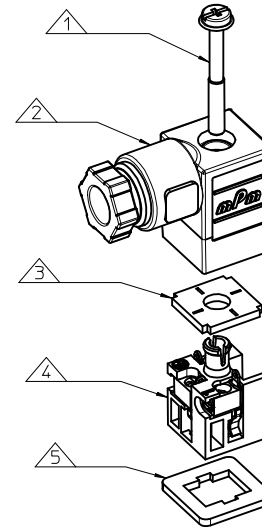

ITEM	DESCRIPTION
1	SCREW
2	COVER ASSEMBLY
3	PCB
4	INSERT ASSEMBLY
5	GASKET

S19207TA022**

SERIES
S19= INTERNAL THREAD FORM C MICRO
POLES
2= 2 POLE & 3= 3 POLE
THREAD
07= PG7, M2= M12x1.5
MATERIAL AND HOUSING COLOUR
G= PA6 GRAY, N= PA6 BLACK, W= PA6 BLACK V0,
T= PA12 TRANSPARENT, B= PA6 WHITE
CIRCUIT
SEE DETAILS IN CATALOGUE
VOLTAGE
SEE DETAILS IN CATALOGUE
SCREW AND GASKET
1= NBR PROFILE GASKET & SCREW
2= NBR FLAT GASKET & SCREW
3= WHITE SILICON PROFILE GASKET & SCREW
4= WHITE SILICON FLAT GASKET & SCREW
A= NBR PROFILE GASKET & SCREW +2mm
B= NBR FLAT GASKET & SCREW +2mm
NON STANDARD COMPONENTS
14= PACKED IN NEUTRAL BAG
5N= PACKED IN BOXES OF 200

NOTES






- PLEASE SEE SHEET 2 FOR CURRENTLY CONFIGURED PART NUMBERS.
FOR SPECIFIC PART NUMBERS PLEASE CONTACT SALES OR CONSULT
THE INTELLIGENT PART NUMBERS IN THE TABLE ATTACHED.
- EARTH POSITION SHOWN, H6.
- FOR PACKAGING SEE PACKAGING SPEC PK 121065-S19
- PRODUCT SPEC: SEE PS-121201-001

LAST INSPECTION NUMBER 2


REMOVED PART NO: EC NO: IPG2014-1527 DRAWN: KNOXMOYLE 2014/02/26 CHKD: OSHEA 2014/03/06 APPR: STGRiffin 2014/04/01	QUALITY SYMBOLS ▽=0 ▽=0	DESCRIPTION	GENERAL TOLERANCES (UNLESS SPECIFIED)		DIMENSION STYLE MM ONLY		SCALE 2:1	DESIGN UNITS METRIC	 THIRD ANGLE PROJECTION
					DRAWN BY JOCONNOR	DATE 2011/05/18	TITLE S19 SERIES INTERNAL THREAD MOLEX MOLEX INCORPORATED		
					CHECKED BY DMAHER	DATE 2011/05/18			
					APPROVED BY EFOLAN	DATE 2011/06/07			
					MATERIAL NO.				
REV			DRAFT WHERE APPLICABLE MUST REMAIN WITHIN DIMENSIONS		SEE SHEET 2		SD-121064-003		SHEET NO. 1 OF 2
					SIZE A2		THIS DRAWING CONTAINS INFORMATION THAT IS PROPRIETARY TO MOLEX INCORPORATED AND SHOULD NOT BE USED WITHOUT WRITTEN PERMISSION		

13	12	11	10	9	8	7	6	5	4	3	2	1
PART No.	mPm PART No.	DESCRIPTION	CIRCUIT	VOLTAGE	COLOUR							
1210640794	S19207NE052	TYPE C MICRO 2P PG7 BLACK NBR FLAT GASKET	E0	230V	DIODE							
1210640798	S19207TA022	TYPE C MICRO 2P PG7 TRANSPARENT NBR FLAT GASKET	A0	24V	RED LED/LAMP							
1210640804	S19207TA052	TYPE C MICRO 2P PG7 TRANSPARENT NBR FLAT GASKET	A0	230V	RED LED/LAMP							
1210640807	S19207TA11A	TYPE C MICRO 2P PG7 TRANSPARENT NBR PROFILE GASKET & SCREW +2mm	A1	12V	RED LED/LAMP							
1210640808	S19207TA121	TYPE C MICRO 2P PG7 TRANSPARENT NBR PROFILE GASKET	A1	24V	RED LED/LAMP							
1210640809	S19207TA122	TYPE C MICRO 2P PG7 TRANSPARENT NBR FLAT GASKET	A1	24V	RED LED/LAMP							
1210640812	S19207TA12A	TYPE C MICRO 2P PG7 TRANSPARENT NBR PROFILE GASKET & SCREW +2mm	A1	24V	RED LED/LAMP							
1210640818	S19207TA142	TYPE C MICRO 2P PG7 TRANSPARENT NBR FLAT GASKET	A1	115V	RED LED/LAMP							
1210640820	S19207TA14A	TYPE C MICRO 2P PG7 TRANSPARENT NBR PROFILE GASKET & SCREW +2mm	A1	115V	RED LED/LAMP							
1210640825	S19207TA1B2	TYPE C MICRO 2P PG7 TRANSPARENT NBR FLAT GASKET	A1	24V	GREEN LED							
1210640828	S19207TC022	TYPE C MICRO 2P PG7 TRANSPARENT NBR FLAT GASKET	C0	24V	RED LED/LAMP							
1210640834	S19207TC122	TYPE C MICRO 2P PG7 TRANSPARENT NBR FLAT GASKET	C1	24V	RED LED/LAMP							
1210640838	S19207TC321	TYPE C MICRO 2P PG7 TRANSPARENT NBR PROFILE GASKET	C3	24V	RED LED/LAMP							
1210640839	S19207TC322	TYPE C MICRO 2P PG7 TRANSPARENT NBR FLAT GASKET	C3	24V	RED LED/LAMP							
1210640846	S19207TC3H1	TYPE C MICRO 2P PG7 TRANSPARENT NBR PROFILE GASKET	C3	24V	AMBER LED							
1210640847	S19207TC3H2	TYPE C MICRO 2P PG7 TRANSPARENT NBR FLAT GASKET	C3	24V	AMBER LED							
1210640851	S19207TC412	TYPE C MICRO 2P PG7 TRANSPARENT NBR FLAT GASKET	C4	12V	RED LED/LAMP							
1210640852	S19207TC421	TYPE C MICRO 2P PG7 TRANSPARENT NBR PROFILE GASKET	C4	24V	RED LED/LAMP							
1210640853	S19207TC422	TYPE C MICRO 2P PG7 TRANSPARENT NBR FLAT GASKET	C4	24V	RED LED/LAMP							
1210640854	S19207TC42A	TYPE C MICRO 2P PG7 TRANSPARENT NBR PROFILE GASKET & SCREW +2mm	C4	24V	RED LED/LAMP							
1210640857	S19207TC441	TYPE C MICRO 2P PG7 TRANSPARENT NBR PROFILE GASKET	C4	115V	RED LED/LAMP							
1210640858	S19207TC442	TYPE C MICRO 2P PG7 TRANSPARENT NBR FLAT GASKET	C4	115V	RED LED/LAMP							
1210640863	S19207TC4B2	TYPE C MICRO 2P PG7 TRANSPARENT NBR FLAT GASKET	C4	24V	GREEN LED							
1210640867	S19207TC4D2	TYPE C MICRO 2P PG7 TRANSPARENT NBR FLAT GASKET	C4	115V	GREEN LED							
1210640869	S19207TC4E2	TYPE C MICRO 2P PG7 TRANSPARENT NBR FLAT GASKET	C4	230V	GREEN LED							
1210640871	S19207TC4H1	TYPE C MICRO 2P PG7 TRANSPARENT NBR PROFILE GASKET	C4	24V	AMBER LED							
1210640872	S19207TC4H2	TYPE C MICRO 2P PG7 TRANSPARENT NBR FLAT GASKET	C4	24V	AMBER LED							
1210641256	S19207TA021	TYPE C MICRO 2P PG7 TRANSPARENT NBR PROFILE GASKET	A0	24V	RED LED/LAMP							
1210641294	S19207TC4B1	TYPE C MICRO 2P PG7 TRANSPARENT NBR PROFILE GASKET	C4	24V	GREEN LED							
1210641445	S19207TA051	TYPE C MICRO 2P PG7 TRANSPARENT NBR PROFILE GASKET	A0	230V	RED LED/LAMP							
1210641465	S19207TC323	TYPE C MICRO 2P PG7 TRANSPARENT WHITE SILICON PROFILE GASKET	C3	24V	RED LED/LAMP							
1210641541	S192M2TC4H1	TYPE C MICRO 2P M12x1.5 TRANSPARENT NBR PROFILE GASKET	C4	24V	AMBER LED							
1210641550	S192M2TA121	TYPE C MICRO 2P M12x1.5 TRANSPARENT NBR PROFILE GASKET	A1	24V	RED LED/LAMP							
1210641559	S19207NE051	TYPE C MICRO 2P PG7 BLACK NBR PROFILE GASKET	E0	230V	DIODE							
1210641710	S19207TC4C3	TYPE C MICRO 2P PG7 TRANSPARENT WHITE SILICON PROFILE GASKET	C4	48V	GREEN LED							
1210641718	S19207TC4L1	TYPE C MICRO 2P PG7 TRANSPARENT NBR PROFILE GASKET	C4	115V	AMBER LED							
1210641727	S19207TC4L2	TYPE C MICRO 2P PG7 TRANSPARENT NBR FLAT GASKET	C4	115V	AMBER LED							
1210641728	S19207TA1H1	TYPE C MICRO 2P PG7 TRANSPARENT NBR PROFILE GASKET	A1	24V	AMBER LED							
1210641729	S19207TA1L1	TYPE C MICRO 2P PG7 TRANSPARENT NBR PROFILE GASKET	A1	115V	AMBER LED							
1210650292	S19207TC4225N	TYPE C MICRO 2P PG7 TRANSPARENT NBR FLAT GASKET IN BOX OF 200	C4	24V	RED LED/LAMP							
1210650511	S19207TC42214	TYPE C MICRO 2P PG7 TRANSPARENT NBR FLAT GASKET IN NEUTRAL BAG	C4	24V	RED LED/LAMP							
1210641766	S19207TA1D1	TYPE C MICRO 2P PG7 TRANSPARENT NBR PROFILE GASKET	A1	115V	GREEN LED							
1210641797	S19207NE051P7	TYPE C MICRO 2P PG7 BLACK NBR PROFILE GASKET, IP67 COMPLIANT	E0	230V	DIODE							
1210641342	S19207TC4M1	TYPE C MICRO 2P PG7 TRANSPARENT NBR PROFILE GASKET	C4	230V	AMBER LED							

SEE SHEET ONE EC NO: IPG2014-1527 FORMAKNORWYLE 2014/02/26 CHYKDQSHA 2014/03/06 APPR:STGRFFIN 2014/04/01	DESCRIPTION  = 0  = 0	QUALITY SYMBOLS	GENERAL TOLERANCES (UNLESS SPECIFIED) <table border="1"> <thead> <tr> <th></th> <th>mm</th> <th>INCH</th> </tr> </thead> <tbody> <tr> <td>4 PLACES</td> <td>± ---</td> <td>± ---</td> </tr> <tr> <td>3 PLACES</td> <td>± ---</td> <td>± ---</td> </tr> <tr> <td>2 PLACES</td> <td>± 0.10</td> <td>± ---</td> </tr> <tr> <td>1 PLACE</td> <td>± 0.20</td> <td>± ---</td> </tr> </tbody> </table>		mm	INCH	4 PLACES	± ---	± ---	3 PLACES	± ---	± ---	2 PLACES	± 0.10	± ---	1 PLACE	± 0.20	± ---	DIMENSION STYLE MM ONLY <table border="1"> <thead> <tr> <th>DRAWN BY</th> <th>DATE</th> </tr> </thead> <tbody> <tr> <td>JOCONNOR</td> <td>2011/05/18</td> </tr> <tr> <th>CHECKED BY</th> <th>DATE</th> </tr> <tr> <td>DMAHER</td> <td>2011/05/18</td> </tr> <tr> <th>APPROVED BY</th> <th>DATE</th> </tr> <tr> <td>EFOLAN</td> <td>2011/06/07</td> </tr> </tbody> </table>	DRAWN BY	DATE	JOCONNOR	2011/05/18	CHECKED BY	DATE	DMAHER	2011/05/18	APPROVED BY	DATE	EFOLAN	2011/06/07	SCALE 2:1	DESIGN UNITS METRIC	THIRD ANGLE PROJECTION 
			mm	INCH																														
		4 PLACES	± ---	± ---																														
		3 PLACES	± ---	± ---																														
		2 PLACES	± 0.10	± ---																														
1 PLACE	± 0.20	± ---																																
DRAWN BY	DATE																																	
JOCONNOR	2011/05/18																																	
CHECKED BY	DATE																																	
DMAHER	2011/05/18																																	
APPROVED BY	DATE																																	
EFOLAN	2011/06/07																																	
				S19 SERIES INTERNAL THREAD																														
				 MOLEX INCORPORATED																														
				MATERIAL NO.		DOCUMENT NO.		SHEET NO.																										
			DRAFT WHERE APPLICABLE MUST REMAIN WITHIN DIMENSIONS	SEE CHART		SD-121064-003		2 OF 2																										
			SIZE A2	THIS DRAWING CONTAINS INFORMATION THAT IS PROPRIETARY TO MOLEX INCORPORATED AND SHOULD NOT BE USED WITHOUT WRITTEN PERMISSION																														

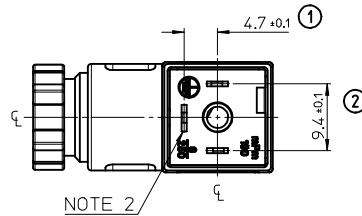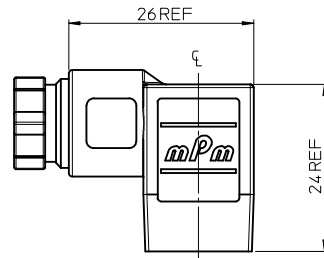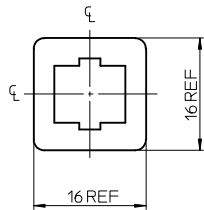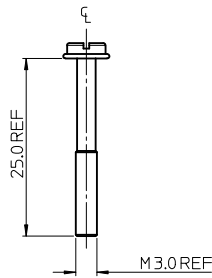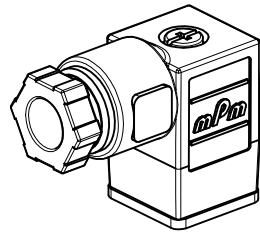

NOTE 2

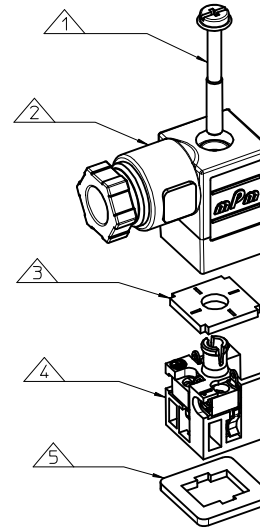

ITEM	DESCRIPTION
1	SCREW
2	COVER ASSEMBLY
3	PCB
4	INSERT ASSEMBLY
5	GASKET

S19207TA022**

SERIES
S19= INTERNAL THREAD FORM C MICRO
POLES
2= 2 POLE & 3= 3 POLE
THREAD
07= PG7, M2= M12x1.5
MATERIAL AND HOUSING COLOUR
G= PA6 GRAY, N= PA6 BLACK, W= PA6 BLACK V0,
T= PA12 TRANSPARENT, B= PA6 WHITE
CIRCUIT
SEE DETAILS IN CATALOGUE
VOLTAGE
SEE DETAILS IN CATALOGUE
SCREW AND GASKET
1= NBR PROFILE GASKET & SCREW
2= NBR FLAT GASKET & SCREW
3= WHITE SILICON PROFILE GASKET & SCREW
4= WHITE SILICON FLAT GASKET & SCREW
A= NBR PROFILE GASKET & SCREW +2mm
B= NBR FLAT GASKET & SCREW +2mm
NON STANDARD COMPONENTS
14= PACKED IN NEUTRAL BAG
5N= PACKED IN BOXES OF 200

NOTES

- PLEASE SEE SHEET 2 FOR CURRENTLY CONFIGURED PART NUMBERS.
FOR SPECIFIC PART NUMBERS PLEASE CONTACT SALES OR CONSULT
THE INTELLIGENT PART NUMBERS IN THE TABLE ATTACHED.
- EARTH POSITION SHOWN, H6.
- FOR PACKAGING SEE PACKAGING SPEC PK 121065-S19
- PRODUCT SPEC: SEE PS-121201-001

LAST INSPECTION NUMBER 2

REMOVED PART NO: EC NO: IPG2014-1527 DRAWN: KNOXMOYLE 2014/02/26 CHKD: OSHEA 2014/03/06 APPR: STGRiffin 2014/04/01	QUALITY SYMBOLS ▽=0 ▽=0	DESCRIPTION	GENERAL TOLERANCES (UNLESS SPECIFIED)		DIMENSION STYLE MM ONLY		SCALE 2:1	DESIGN UNITS METRIC	 THIRD ANGLE PROJECTION	
				mm	INCH	DRAWN BY JOCONNOR	DATE 2011/05/18	TITLE S19 SERIES INTERNAL THREAD  MOLEX INCORPORATED		
			4 PLACES	± ---	± ---	CHECKED BY DMAHER	DATE 2011/05/18			
			3 PLACES	± ---	± ---	APPROVED BY EFOLAN	DATE 2011/06/07			
			2 PLACES	± 0.10	± ---	MATERIAL NO.	DOCUMENT NO.			
	1 PLACE	± 0.20	± ---	ANGULAR ± 2 °		SD-121064-003		SHEET NO. 1 OF 2		
REV			DRAFT WHERE APPLICABLE MUST REMAIN WITHIN DIMENSIONS		SEE SHEET 2		SIZE A2		THIS DRAWING CONTAINS INFORMATION THAT IS PROPRIETARY TO MOLEX INCORPORATED AND SHOULD NOT BE USED WITHOUT WRITTEN PERMISSION	

13	12	11	10	9	8	7	6	5	4	3	2	1
PART No.	mPm PART No.	DESCRIPTION	CIRCUIT	VOLTAGE	COLOUR							
1210640794	S19207NE052	TYPE C MICRO 2P PG7 BLACK NBR FLAT GASKET	E0	230V	DIODE							
1210640798	S19207TA022	TYPE C MICRO 2P PG7 TRANSPARENT NBR FLAT GASKET	A0	24V	RED LED/LAMP							
1210640804	S19207TA052	TYPE C MICRO 2P PG7 TRANSPARENT NBR FLAT GASKET	A0	230V	RED LED/LAMP							
1210640807	S19207TA11A	TYPE C MICRO 2P PG7 TRANSPARENT NBR PROFILE GASKET & SCREW +2mm	A1	12V	RED LED/LAMP							
1210640808	S19207TA121	TYPE C MICRO 2P PG7 TRANSPARENT NBR PROFILE GASKET	A1	24V	RED LED/LAMP							
1210640809	S19207TA122	TYPE C MICRO 2P PG7 TRANSPARENT NBR FLAT GASKET	A1	24V	RED LED/LAMP							
1210640812	S19207TA12A	TYPE C MICRO 2P PG7 TRANSPARENT NBR PROFILE GASKET & SCREW +2mm	A1	24V	RED LED/LAMP							
1210640818	S19207TA142	TYPE C MICRO 2P PG7 TRANSPARENT NBR FLAT GASKET	A1	115V	RED LED/LAMP							
1210640820	S19207TA14A	TYPE C MICRO 2P PG7 TRANSPARENT NBR PROFILE GASKET & SCREW +2mm	A1	115V	RED LED/LAMP							
1210640825	S19207TA1B2	TYPE C MICRO 2P PG7 TRANSPARENT NBR FLAT GASKET	A1	24V	GREEN LED							
1210640828	S19207TC022	TYPE C MICRO 2P PG7 TRANSPARENT NBR FLAT GASKET	C0	24V	RED LED/LAMP							
1210640834	S19207TC122	TYPE C MICRO 2P PG7 TRANSPARENT NBR FLAT GASKET	C1	24V	RED LED/LAMP							
1210640838	S19207TC321	TYPE C MICRO 2P PG7 TRANSPARENT NBR PROFILE GASKET	C3	24V	RED LED/LAMP							
1210640839	S19207TC322	TYPE C MICRO 2P PG7 TRANSPARENT NBR FLAT GASKET	C3	24V	RED LED/LAMP							
1210640846	S19207TC3H1	TYPE C MICRO 2P PG7 TRANSPARENT NBR PROFILE GASKET	C3	24V	AMBER LED							
1210640847	S19207TC3H2	TYPE C MICRO 2P PG7 TRANSPARENT NBR FLAT GASKET	C3	24V	AMBER LED							
1210640851	S19207TC412	TYPE C MICRO 2P PG7 TRANSPARENT NBR FLAT GASKET	C4	12V	RED LED/LAMP							
1210640852	S19207TC421	TYPE C MICRO 2P PG7 TRANSPARENT NBR PROFILE GASKET	C4	24V	RED LED/LAMP							
1210640853	S19207TC422	TYPE C MICRO 2P PG7 TRANSPARENT NBR FLAT GASKET	C4	24V	RED LED/LAMP							
1210640854	S19207TC42A	TYPE C MICRO 2P PG7 TRANSPARENT NBR PROFILE GASKET & SCREW +2mm	C4	24V	RED LED/LAMP							
1210640857	S19207TC441	TYPE C MICRO 2P PG7 TRANSPARENT NBR PROFILE GASKET	C4	115V	RED LED/LAMP							
1210640858	S19207TC442	TYPE C MICRO 2P PG7 TRANSPARENT NBR FLAT GASKET	C4	115V	RED LED/LAMP							
1210640863	S19207TC4B2	TYPE C MICRO 2P PG7 TRANSPARENT NBR FLAT GASKET	C4	24V	GREEN LED							
1210640867	S19207TC4D2	TYPE C MICRO 2P PG7 TRANSPARENT NBR FLAT GASKET	C4	115V	GREEN LED							
1210640869	S19207TC4E2	TYPE C MICRO 2P PG7 TRANSPARENT NBR FLAT GASKET	C4	230V	GREEN LED							
1210640871	S19207TC4H1	TYPE C MICRO 2P PG7 TRANSPARENT NBR PROFILE GASKET	C4	24V	AMBER LED							
1210640872	S19207TC4H2	TYPE C MICRO 2P PG7 TRANSPARENT NBR FLAT GASKET	C4	24V	AMBER LED							
1210641256	S19207TA021	TYPE C MICRO 2P PG7 TRANSPARENT NBR PROFILE GASKET	A0	24V	RED LED/LAMP							
1210641294	S19207TC4B1	TYPE C MICRO 2P PG7 TRANSPARENT NBR PROFILE GASKET	C4	24V	GREEN LED							
1210641445	S19207TA051	TYPE C MICRO 2P PG7 TRANSPARENT NBR PROFILE GASKET	A0	230V	RED LED/LAMP							
1210641465	S19207TC323	TYPE C MICRO 2P PG7 TRANSPARENT WHITE SILICON PROFILE GASKET	C3	24V	RED LED/LAMP							
1210641541	S192M2TC4H1	TYPE C MICRO 2P M12x1.5 TRANSPARENT NBR PROFILE GASKET	C4	24V	AMBER LED							
1210641550	S192M2TA121	TYPE C MICRO 2P M12x1.5 TRANSPARENT NBR PROFILE GASKET	A1	24V	RED LED/LAMP							
1210641559	S19207NE051	TYPE C MICRO 2P PG7 BLACK NBR PROFILE GASKET	E0	230V	DIODE							
1210641710	S19207TC4C3	TYPE C MICRO 2P PG7 TRANSPARENT WHITE SILICON PROFILE GASKET	C4	48V	GREEN LED							
1210641718	S19207TC4L1	TYPE C MICRO 2P PG7 TRANSPARENT NBR PROFILE GASKET	C4	115V	AMBER LED							
1210641727	S19207TC4L2	TYPE C MICRO 2P PG7 TRANSPARENT NBR FLAT GASKET	C4	115V	AMBER LED							
1210641728	S19207TA1H1	TYPE C MICRO 2P PG7 TRANSPARENT NBR PROFILE GASKET	A1	24V	AMBER LED							
1210641729	S19207TA1L1	TYPE C MICRO 2P PG7 TRANSPARENT NBR PROFILE GASKET	A1	115V	AMBER LED							
1210650292	S19207TC4225N	TYPE C MICRO 2P PG7 TRANSPARENT NBR FLAT GASKET IN BOX OF 200	C4	24V	RED LED/LAMP							
1210650511	S19207TC42214	TYPE C MICRO 2P PG7 TRANSPARENT NBR FLAT GASKET IN NEUTRAL BAG	C4	24V	RED LED/LAMP							
1210641766	S19207TA1D1	TYPE C MICRO 2P PG7 TRANSPARENT NBR PROFILE GASKET	A1	115V	GREEN LED							
1210641797	S19207NE051P7	TYPE C MICRO 2P PG7 BLACK NBR PROFILE GASKET, IP67 COMPLIANT	E0	230V	DIODE							
1210641342	S19207TC4M1	TYPE C MICRO 2P PG7 TRANSPARENT NBR PROFILE GASKET	C4	230V	AMBER LED							

SEE SHEET ONE EC NO: IPG2014-1527 DRWKNR00VYLE 2014/02/26 CHKDQSHHA 2014/03/06 APPR:STGRJFIN 2014/04/01	QUALITY SYMBOLS	GENERAL TOLERANCES (UNLESS SPECIFIED)		DIMENSION STYLE MM ONLY		SCALE 2:1	DESIGN UNITS METRIC	THIRD ANGLE PROJECTION
	DESCRIPTION	mm	INCH	DRAWN BY JOCONNOR	DATE 2011/05/18	S19 SERIES INTERNAL THREAD		
	4 PLACES	± ---	± ---	CHECKED BY	DATE			
	3 PLACES	± ---	± ---	DMAHER	2011/05/18			
	2 PLACES	± 0.10	± ---	APPROVED BY	DATE			
	1 PLACE	± 0.20	± ---	EFOLAN	2011/06/07	MOLEX MOLEX INCORPORATED		
	ANGULAR ± 2 °			MATERIAL NO.	DOCUMENT NO.			SHEET NO.
	DRAFT WHERE APPLICABLE MUST REMAIN WITHIN DIMENSIONS			SEE CHART		SD-121064-003		2 OF 2
	REV	THIS DRAWING CONTAINS INFORMATION THAT IS PROPRIETARY TO MOLEX INCORPORATED AND SHOULD NOT BE USED WITHOUT WRITTEN PERMISSION						

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

[1210640846](#) [1210641559](#) [1210640794](#)