

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1300060302

Status:

Active

Overview:


Brad Mini-Change Connectors

Description:

Mini-Change A-Size Single-Ended Cordset, 3 Poles, Female (Straight) to Pigtail, 18 AWG, PVC Cable, 1.83m (6.0') Length

Documents:	
Drawing (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR6837
UL	E152210
General	
Product Family	Industrial Cordsets
Series	130006
Connector End A	Mini-Change
Connector End B	Pigtail
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	Brad Mini-Change Connectors
Product Name	Mini-Change
Protocol	N/A
Region	America
Type	Single Ended
UPC	78678841851
Physical	
Cable Diameter	7.14mm (.281")
Cable Length	1.83m (6.0')
Color - Cable Jacket	Yellow
Coupling Style	Threaded
Gender	Female-Pigtail
Keyway	Single
LED Indicator	No
Material - Cable Jacket	PVC
Material - Connector Body	TPE
Material - Coupling Nut	Black Epoxy Coated Zinc
Material - Plating Mating	Gold
Net Weight	88.740/g
Orientation	Straight to Pigtail
Poles	3
Temperature Range - Operating	-20°C to +105°C
Wire Size AWG	18
Wire/Cable Type	UL 2661
Electrical	
Current - Maximum per Contact	10.0A
Voltage - Maximum	300V
Material Info	
Engineering Number	103000A03F060
Reference - Drawing Numbers	
Sales Drawing	SD-130006-029-001, SD-130006-070-001

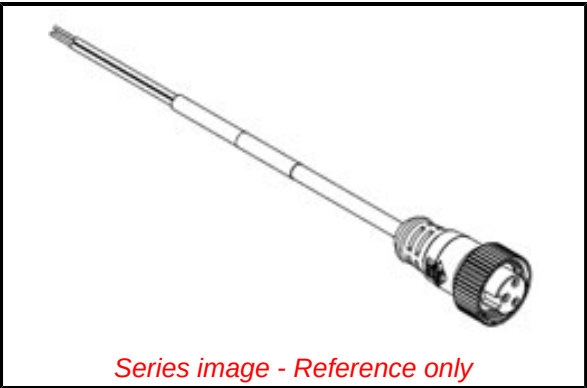

Series image - Reference only

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Contained Per - D(2021)4569-DC (8 July 2021)	
Lead	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

130006 Series

This document was generated on 09/08/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[130006-0302](#)