

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1300070051

Status:


Active

Overview:

Brad Mini-Change Connectors

Description:

Mini-Change B-Size Single-Ended Cordset, 6 Poles, Male (Straight) to Pigtail, 16 AWG, Yellow PVC Cable, 1.83m (6.0') Length

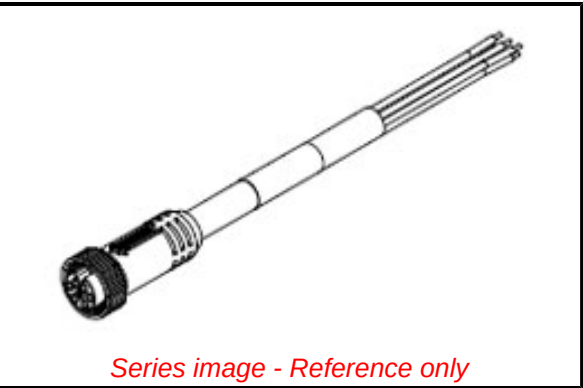

Series image - Reference only

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR6837
UL	E152210
General	
Product Family	Industrial Cordsets
Series	130007
Connector End A	Mini-Change
Connector End B	Pigtail
IP Rating	IP67
Material - Contact	Brass
Overview	Brad Mini-Change Connectors
Product Name	Mini-Change
Protocol	DeviceNet
Region	America
Type	Single Ended
UPC	78678843983
Physical	
Cable Diameter	13.72mm (.540")
Cable Length	1.83m (6.0')
Color - Cable Jacket	Yellow
Coupling Style	Threaded
Gender	Male-Pigtail
Keyway	Single
LED Indicator	No
Material - Cable Jacket	PVC
Material - Connector Body	TPE
Material - Coupling Nut	Black Epoxy Coated Zinc
Material - Plating Mating	Gold
Net Weight	125.000/g
Orientation	Straight to Pigtail
Poles	6
Temperature Range - Operating	-20° to +105°C
Wire Size AWG	16
Wire/Cable Type	STOOW
Electrical	
Current - Maximum per Contact	8.0A
Voltage - Maximum	600V
Material Info	
Engineering Number	206002A01F060
Reference - Drawing Numbers	
Sales Drawing	SD-130007-002-001

EU ELV

Compliant with
Exemption 3

EU RoHS

Compliant with
Exemption 6(c)

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China RoHS

China ROHS

ELV

Not Relevant

Compliant with
Exemption 3

RoHS Phthalates

Not Contained

Search Parts in this Series

130007 Series

This document was generated on 01/07/2022

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1300070051