

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300070177](#)
Status: **Active**
Overview: [Brad Mini-Change Connectors](#)
Description: Mini-Change Single-Ended Straight Cordset, 8 Poles, B-Size Mini, Female (Straight) to Pigtail, 22 AWG, PVC Cable, 10.0m (32.81') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837

General

Product Family Industrial Cordsets
Series [130007](#)
Connector End A Mini-Change
Connector End B Pigtail
IP Rating IP67
Material - Contact Brass
Overview [Brad Mini-Change Connectors](#)
Product Name Mini-Change
Protocol DeviceNet
Region America
Type Single Ended
UPC 78678840190

Physical

Cable Diameter 6.10mm (.240")
Cable Length 10.0m (32.81')
Color - Cable Jacket Yellow
Coupling Style Push to Lock
Gender Female-Pigtail
Keyway Single
LED Indicator No
Material - Cable Jacket PVC
Material - Connector Body PVC
Material - Coupling Nut Black Epoxy Coated Zinc
Material - Plating Mating Gold
Orientation Straight to Pigtail
Poles 8
Temperature Range - Operating -20° to +75°C
Wire Size AWG 22
Wire/Cable Type ST00W

Electrical


Current - Maximum per Contact 2.5A
Voltage - Maximum 600V

Material Info

Engineering Number 208000A04M100

Reference - Drawing Numbers

Sales Drawing SD-130007-007-001

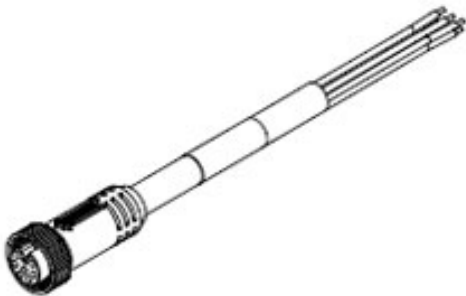

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China RoHS

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

[130007](#) Series

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1300070177