

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1300080011

Status:


Active

Overview:

Brad Mini-Change Connectors

Description:

Mini-Change C-Size Single-Ended Cordset, 9 Poles, Female (Straight) to Pigtail, 16 AWG, PVC Cable, 4.60m (15.09') Length

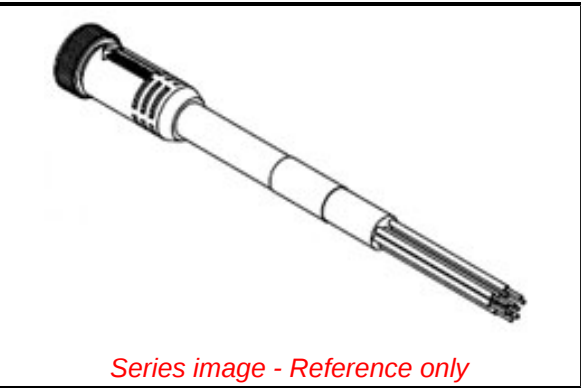

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

|                               |                             |
|-------------------------------|-----------------------------|
| Agency Certification          |                             |
| CSA                           | LR6837                      |
| UL                            | E152210                     |
| General                       |                             |
| Product Family                | Industrial Cordsets         |
| Series                        | 130008                      |
| Connector End A               | Mini-Change                 |
| Connector End B               | Pigtail                     |
| IP Rating                     | IP67                        |
| Material - Contact            | Brass                       |
| Overview                      | Brad Mini-Change Connectors |
| Product Name                  | Mini-Change                 |
| Protocol                      | DeviceNet                   |
| Region                        | America                     |
| Type                          | Single Ended                |
| UPC                           | 78678807567                 |
| Physical                      |                             |
| Cable Diameter                | 16.26mm (.640")             |
| Cable Length                  | 4.60m (15.09')              |
| Color - Cable Jacket          | Yellow                      |
| Coupling Style                | Threaded                    |
| Gender                        | Female-Pigtail              |
| Keyway                        | Single                      |
| LED Indicator                 | No                          |
| Material - Cable Jacket       | PVC                         |
| Material - Connector Body     | PVC                         |
| Material - Coupling Nut       | Black Epoxy Coated Zinc     |
| Material - Plating Mating     | Gold                        |
| Orientation                   | Straight to Pigtail         |
| Poles                         | 9                           |
| Temperature Range - Operating | -20° to +105°C              |
| Wire Size AWG                 | 16                          |
| Wire/Cable Type               | STOOW                       |
| Electrical                    |                             |
| Current - Maximum per Contact | 7.0A                        |
| Voltage - Maximum             | 600V                        |
| Material Info                 |                             |
| Engineering Number            | 309000A01F150               |
| Reference - Drawing Numbers   |                             |
| Sales Drawing                 | SD-130008-004-001           |

|                                                               |              |
|---------------------------------------------------------------|--------------|
| EU ELV                                                        |              |
| Not Relevant                                                  |              |
| EU RoHS                                                       | China RoHS   |
| Not Reviewed                                                  |              |
| REACH SVHC                                                    |              |
| Not Reviewed                                                  |              |
| Halogen-Free                                                  |              |
| Status                                                        |              |
| Not Reviewed                                                  |              |
| For more information, please visit <a href="#">Contact US</a> |              |
| China ROHS                                                    | Not Reviewed |
| ELV                                                           | Not Relevant |
| RoHS Phthalates                                               | Not Reviewed |

Search Parts in this Series

130008 Series

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1300080011