

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1300080303

Status:


Active

Overview:

Brad Mini-Change Connectors

Description:

Mini-Change C-Size Single-Ended Cordset, 19 Poles, Female (Straight) to Pigtail, 18 and 22 AWG, PUR Cable, 5.0m (16.40') Length

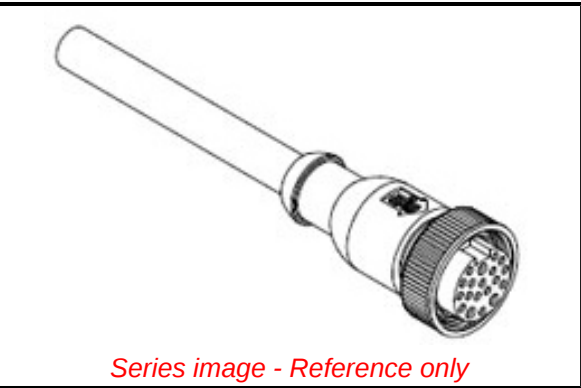

Series image - Reference only

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Industrial Cordsets
Series	130008
Connector End A	Mini-Change
Connector End B	Pigtail
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	Brad Mini-Change Connectors
Product Name	Mini-Change
Protocol	DeviceNet
Region	Europe
Type	Single Ended
UPC	78678841459
Physical	
Cable Diameter	11.43mm (.450")
Cable Length	5.0m (16.40')
Color - Cable Jacket	Black
Coupling Style	Threaded
Gender	Female-Pigtail
Keyway	Single
LED Indicator	No
Material - Cable Jacket	PUR
Material - Connector Body	PVC
Material - Coupling Nut	Black Epoxy Coated Zinc
Material - O-Ring	Fluoro-elastomer
Material - Plating Mating	Gold
Net Weight	22945.990/g
Orientation	Straight to Pigtail
Poles	19
Temperature Range - Operating	-20°C to +80°C
Wire Size AWG	18, 22
Wire/Cable Type	N/A
Electrical	
Current - Maximum per Contact	2.0A, 3.0A
Voltage - Maximum	300V AC/DC
Material Info	
Engineering Number	303000P80M050
Reference - Drawing Numbers	
Sales Drawing	SD-130008-006-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Contained Per - D(2020)9139-DC (19 Jan 2021)	
Lead	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

130008 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

130008-0303