

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300100311](#)
Status: **Active**
Overview: [Brad Mini-Change Connectors](#)
Description: Mini-Change A-Size Double-Ended Cordset, 3 Poles, Male (Straight) to Female (Straight), 16 AWG, Rubber Cable, 2.74m (9.0') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837

General

Product Family Industrial Cordsets
Series [130010](#)
Connector End A Mini-Change
Connector End B Mini-Change
IP Rating IP67
Material - Contact Copper Alloy
Overview [Brad Mini-Change Connectors](#)
Product Name Mini-Change
Protocol DeviceNet
Region America
Type Double Ended
UPC 78678842260

Physical

Cable Diameter 10.67mm (.420")
Cable Length 2.74m (9.0')
Color - Cable Jacket Yellow
Coupling Style Threaded
Gender Female-Male
Keyway Single
LED Indicator No
Material - Cable Jacket Rubber
Material - Connector Body PVC
Material - Coupling Nut Black Epoxy Coated Zinc
Material - Plating Mating Gold
Orientation Straight to Straight
Poles 3
Temperature Range - Operating -20° to +90°C
Wire Size AWG 16
Wire/Cable Type SOO

Electrical


Current - Maximum per Contact 13.0A
Voltage - Maximum 600V

Material Info

Engineering Number 113020C01F090

Reference - Drawing Numbers

Sales Drawing SD-130010-010-001

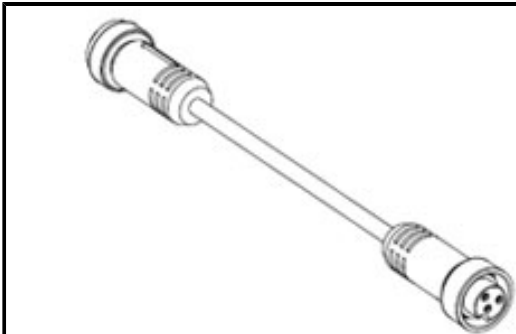

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

[130010 Series](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1300100311