

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300100794](#)
Status: **Active**
Overview: [Brad Mini-Change Connectors](#)
Description: Mini-Change A-Size Double-Ended Cordset, 4 Poles, Male (Straight) to Female (Straight), 16 AWG, PVC Cable, 1.0m (3.28') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837

General

Product Family Industrial Cordsets
Series [130010](#)
Connector End A Mini-Change
Connector End B Mini-Change
IP Rating IP67
Material - Contact Copper Alloy
Overview [Brad Mini-Change Connectors](#)
Product Name Mini-Change
Protocol DeviceNet
Region America
Type Double Ended
UPC 78678837045

Physical

Cable Diameter 11.18mm (.440")
Cable Length 1.0m (3.28')
Color - Cable Jacket Yellow
Coupling Style Threaded
Gender Female-Male
Keyway Single
LED Indicator No
Material - Cable Jacket PVC
Material - Connector Body TPE
Material - Coupling Nut Black Epoxy Coated Zinc
Material - Plating Mating Gold
Net Weight 111.000/g
Orientation Straight to Straight
Poles 4
Temperature Range - Operating -20°C to +105°C
Wire Size AWG 16
Wire/Cable Type ST00W

Electrical


Current - Maximum per Contact 10.0A
Voltage - Maximum 600V

Material Info

Engineering Number 114030A38M010

Reference - Drawing Numbers

Sales Drawing SD-130010-013-001

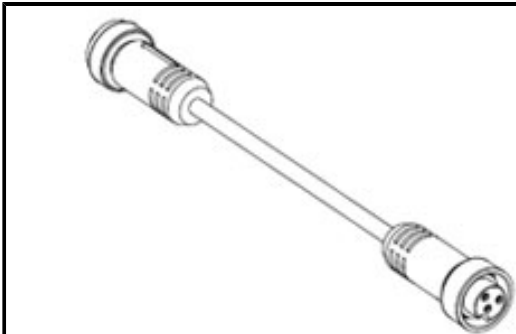

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

**Compliant with
Exemption 6(c)**

REACH SVHC

Contained Per -
D(2021)4569-DC (8
July 2021)
Lead

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[130010 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300100794](#)